


## CS wall-mounted enclosures

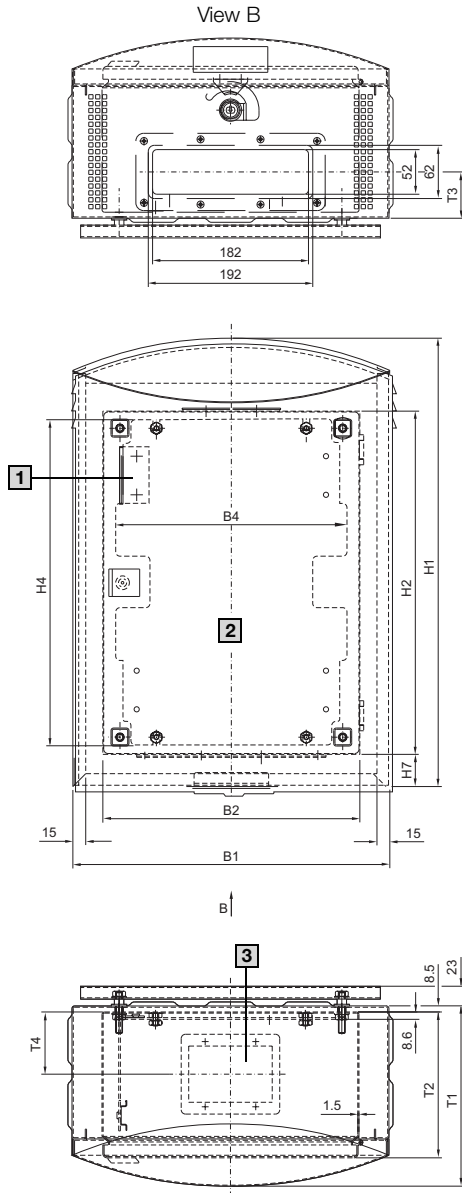

- B1 = Width of outer enclosure
- B2 = Width of inner enclosure
- B3 = Centre-to-centre spacing of attachment C rail/interior enclosure
- B4 = Width of mounting plate
- H1 = Height of outer enclosure
- H2 = Height of inner enclosure
- H3 = Centre-to-centre spacing of attachment C rail/interior enclosure
- H4 = Height of mounting plate
- H5 = Distance from outer enclosure to C rail attachment/interior enclosure
- H7 = Distance from outer enclosure to inner enclosure
- T1 = Depth of outer enclosure
- T2 = Depth of inner enclosure
- T3 = Distance from outer enclosure to centre of bottom gland plate
- T4 = Distance from outer enclosure to centre of top gland plate

- 1** Supply includes: Mounting bracket for thermostat SK 3110.000
- 2** Supports mounting of the mounting plate in the inner enclosure and inner door

- 3** Roof cut-out, inner enclosure with gland plate  
CS 9791.015/.025/.035  
W 97.5 x D 65.5 mm  
CS 9791.045  
W 302.0 x D 122.0 mm

- 4** Lock SZ 2749.000 with lock insert (from B1 = 630 mm, 2 locks)

Enclosure Model No. CS	Width dimensions mm				Height dimensions mm						Depth dimensions mm			
	B1	B2	B3	B4	H1	H2	H3	H4	H5	H7	T1	T2	T3	T4
9791.015	370	300	260	270	522.5	400	360	380	57.5	37.5	210	170	55.5	72.5
9791.025	420	350	310	320	560.5	440	400	410	58	38	210	170	55.5	72.5
9791.035	530	460	420	430	700	565	525	535	63	43	265	220	82	72.5
9791.045	630	580	540	550	780	580	540	550	55	35	380	333	82	155