



紧凑型控制机柜 AE


AE 1001.X00 - AE 1016.X00

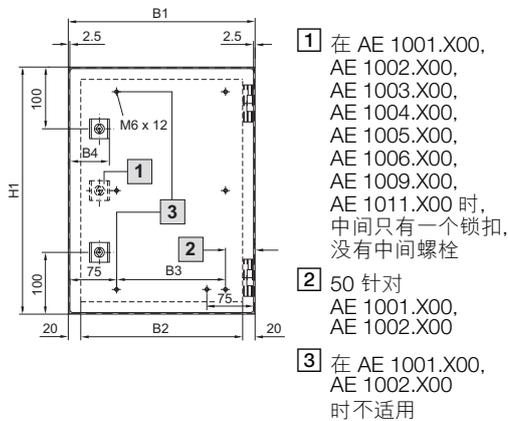


安装板
AE 1001.X00,
AE 1002.X00

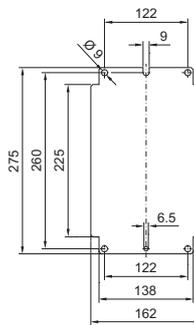


AE 1003.X00 - AE 1016.X00
(AE 1005.500/600 的情况下,
安装板的安装位置转动 90°)

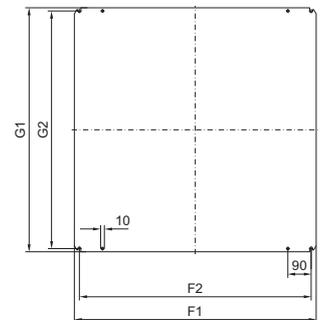


AE 1017.X00

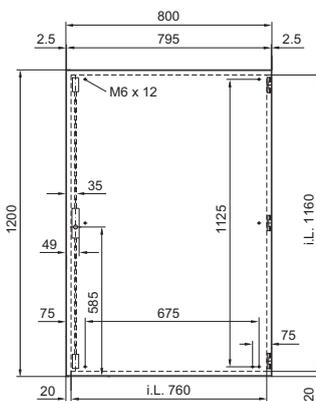


AE 1018.X00 (AE 1019.X00)

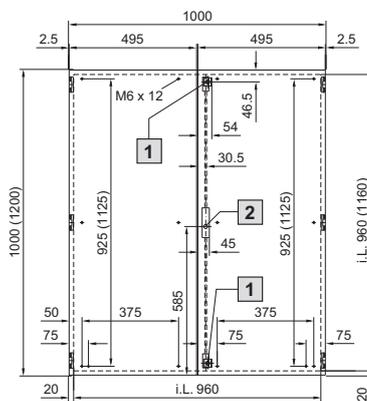

 
- 1 AE 1018.X00 的情况下为锁扣
- 2 AE 1019.X00 的情况下为锁杆



安装板
AE 1018.X00

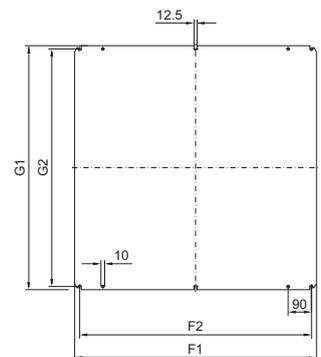

AE 1017.X00 (AE 1019.X00)

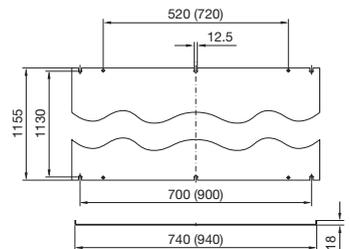

括号中为 AE 1019.X00 的尺寸

型号 AE	宽度尺寸 mm				高度尺寸 mm				深度尺寸 mm		安装板 mm				材料厚度 mm		
	B1	B2	B3	B4	H1	H2	H3	H4	T1	T2	F1	F2	G1	G2	箱体	门	安装板
1001.X00	200	167	-	56	300	295	274	225	122	100	-	-	-	-	1.25	1.5	2.0
1002.X00	200	167	-	56	300	295	274	225	157	135	-	-	-	-	1.25	1.5	2.0
1003.X00	300	260	175	66	300	295	260	225	212	168 - 184	254	215	275	250	1.38	1.5	2.0
1004.X00	380	340	250	66	300	295	260	225	157	113 - 129	334	295	275	250	1.38	1.5	2.0
1011.X00	380	340	250	66	300	295	260	225	212	168 - 184	334	295	275	250	1.38	1.5	2.0
1005.X00	300	260	175	66	380	375	340	275	212	168 - 184	334	295	275	250	1.38	1.5	2.0
1006.X00	380	340	250	66	380	375	340	275	212	168 - 184	334	295	355	330	1.38	1.5	2.0
1015.X00	400	360	275	66	500	495	460	425	212	168 - 184	354	315	475	450	1.38	1.5	2.0
1007.X00	500	460	375	66	500	495	460	425	212	168 - 184	449	410	470	445	1.38	2.0	2.5
1013.X00	500	460	375	66	500	495	460	425	302	258 - 274	449	410	470	445	1.50	2.0	2.5
1008.X00	380	340	250	66	600	595	560	525	212	168 - 184	334	295	570	545	1.38	1.5	2.5
1009.X00	600	560	475	66	380	375	340	275	212	168 - 184	549	510	355	330	1.38	1.5	2.5
1010.X00	600	560	475	66	600	595	560	525	212	168 - 184	549	510	570	545	1.38	2.0	2.5
1012.X00	600	560	475	66	760	755	720	675	212	168 - 184	549	510	730	705	1.38	2.0	3.0
1014.X00	760	720	625	66	760	755	720	675	302	258 - 274	704	665	730	705	1.50	2.0	3.0
1016.X00	800	760	675	66	1000	955	960	925	302	258 - 274	739	700	955	930	1.50	2.0	3.0
1017.X00	800	-	-	-	1200	-	-	-	302	-	-	-	-	-	1.50	2.0	3.0
1018.X00	1000	-	-	-	1000	-	-	-	302	-	939	900	955	930	1.50	2.0	3.0
1019.X00	1000	-	-	-	1200	-	-	-	302	-	-	-	-	-	1.50	2.0	3.0