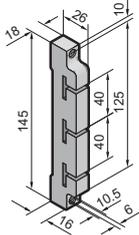
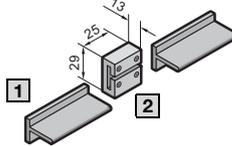


Mini-PLS 母线支架

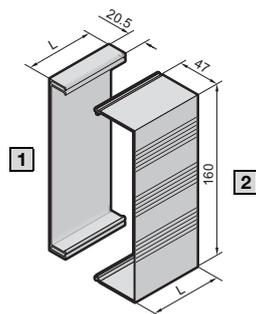
3 极

40 mm 母线中心距离 认证:  E191125	
型号 SV	9600.000 

Mini-PLS 特种母线 E-Cu 和母线连接器

认证:  E191125					
	[1] 母线 (母线横截面积 120 mm ² , 母线厚度 3 mm)				[2] 母线连接器
型号 SV	9601.000 	9602.000 	9603.000 	9624.000 	9611.000 
长度 mm	500	700	1100	1500	-
紧固扭矩 Nm	-				最大 2

Mini-PLS 防接触保护

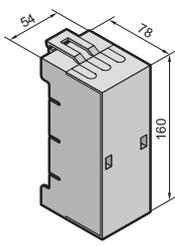
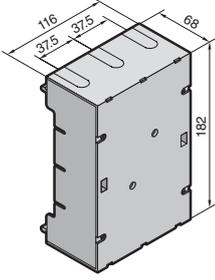
认证:  E191125					
	[1] 底部槽型件			[2] 盖板	
型号 SV	9605.000 	9606.000 	9607.000 	9608.000 	9609.000 
长度 (L) mm	500	700	1100	250	500

配电组件

Mini-PLS 母线系统 (40 mm)

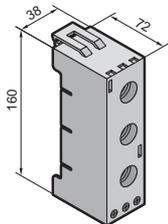
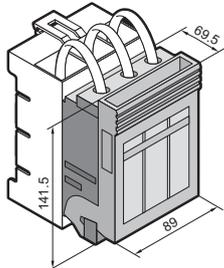
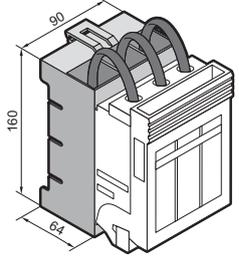
Mini-PLS 连接适配器

3 极

上 / 下电缆出线 说明: 技术信息 用于导线和导线的连接, 参见章节 2-101, 页码 4 认证:  E191125		
最大额定电流	63 A	250 A
额定工作电压	IEC 690 V 交流	690 V 交流
	UL 600 V 交流	600 V 交流
型号 SV	9613.000 	9612.000 
安全参数		
紧固扭矩 Nm 导线连接螺钉	3	6
圆导线的连接 mm ²	1.5 – 35	10 – 120
接线区, 用于叠层铜母线, 宽 x 高 mm	10 x 8	17 x 15

Mini-PLS 熔断器组件

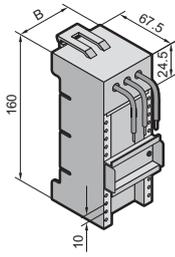
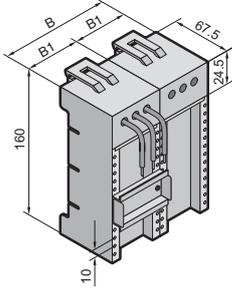
3 极

说明: 其它技术信息 SV 3431.000, 参见章节 2-115, 页码 1			
组件	母线式熔丝座	NH 负荷断路器	用于开关的母线适配器
熔断器	D 02-E 18	-	-
最大额定电流	63 A	100 A	-
额定工作电压	400 V 交流	690 V 交流	-
型号 SV	9630.000	3431.000	9629.100
安全参数			
紧固扭矩 Nm 框型接线柱	2.5	3	-
圆导线的连接 mm ²	1.5 – 16 ¹⁾	1.5 – 50	-
带连接导线 mm ²	-	-	35
接线区, 用于叠层铜母线, 宽 x 高 mm	-	10 x 10	-

¹⁾ 在使用细导线或最细导线 (f) 时, 必须使用电缆芯线端护套

Mini-PLS 元件适配器

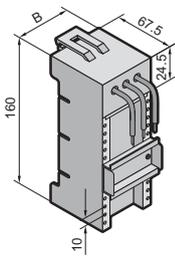
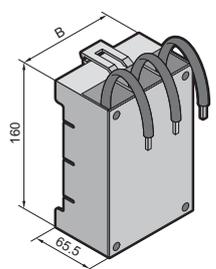
最大额定电流 12 – 25 A, 3 极

说明: 技术信息 连接导线的载流容量, 参见章节 2-101, 页码 5 认证:  E191125							
宽度 (B) mm	45	45	45	54	54	72	90
宽度 (B1) mm	-	-	-	-	-	-	45
最大额定电流	12 A	25 A	25 A	25 A	25 A	25 A	25 A
额定工作电压	IEC 690 V 交流	690 V 交流	690 V 交流	690 V 交流	690 V 交流	690 V 交流	690 V 交流
	UL 600 V 交流	600 V 交流	600 V 交流	600 V 交流	600 V 交流	600 V 交流	600 V 交流
连接电缆 ¹⁾	AWG 14	AWG 12	AWG 12	AWG 12	AWG 12	AWG 12	AWG 12
支承轨高度 mm	7.5	7.5	15	7.5	15	7.5	7.5
型号 SV	9614.110	9614.100	9615.100	9614.000	9615.000	9625.000	9629.010

¹⁾ AWG = 美国线规 · AWG 14 = 2.08 mm² ± 2.5 mm² · AWG 12 = 3.31mm² ± 4 mm²

Mini-PLS 元件适配器

最大额定电流 40 – 100 A, 3 极

说明: 连接电缆载流容量的技术信息, 参见章节 2-101, 页码 5 认证:  E191125					
宽度 (B) mm	54	54	72	72	90
最大额定电流	40 A	40 A	40 A	40 A	100 A
额定工作电压	IEC 690 V 交流	690 V 交流	690 V 交流	690 V 交流	690 V 交流
	UL 600 V 交流	600 V 交流	600 V 交流	600 V 交流	600 V 交流
连接电缆 ¹⁾	AWG 10	AWG 10	AWG 10	AWG 10	35 mm ²
支承轨高度 mm	7.5	15	7.5	15	-
型号 SV	9616.000	9617.000	9627.000	9628.000	9629.000

¹⁾ AWG = 美国线规 AWG 10 = 5.26 mm² ± 6 mm²