
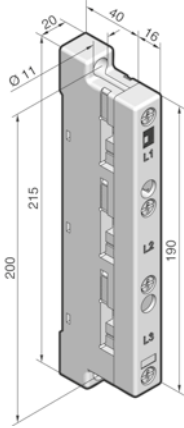
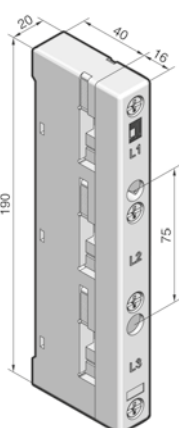
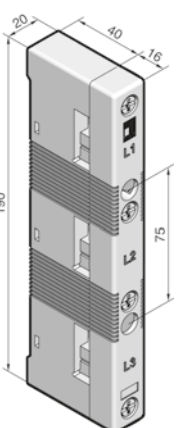
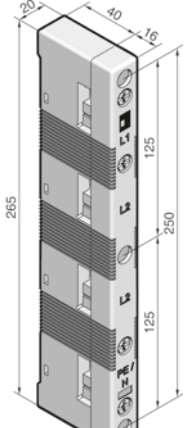


配电组件

RiLine 母线系统 (60 mm)

扁平铜母线系统

可高达 800 A

技术信息 计算 DIN 43 671 标准的额定电流, 参见章节 2-102, 页码 1/2 说明: - UL 认证, 仅适用于与 AC 应用连接 认证:  E191125									
极数		3 极						4 极	
母线中心距离 mm		60						60	
额定工作电压	IEC	1000 V 交流		1000 V 交流		1000 V 交流		1000 V 交流	
	UL	-		-		1500 V 直流		-	
用于母线 mm	12 x 5/10 ¹⁾	■		■		-		■	
	15 x 5 - 25 x 10, 30 x 5	■		■		■		■	
	30 x 10	■		■		■		■	
应用		IEC		IEC		IEC/UL		IEC/UL	
型号 SV		9340.010		9340.000		9340.050 ²⁾ (UL)		9340.004 ²⁾ (UL)	
按 IEC (DIN EN)/UL 应用的安装参数									
紧固扭矩 Nm									
- 固定螺栓									
M5 x 16		5		5		5		-	
M5 x 25		-		-		-		-	
M6 x 25		-		-		-		-	
- 顶盖固定装置		3		3		3		3	

¹⁾ 在使用 12 x 5/10 mm 的母线时, 需要附加间隔垫片 SV 9340.090

²⁾ 对于 UL 应用需要使用底槽