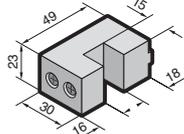


配电组件

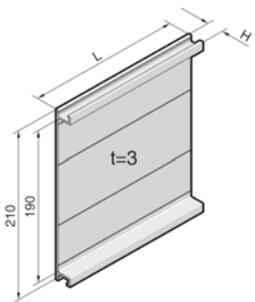
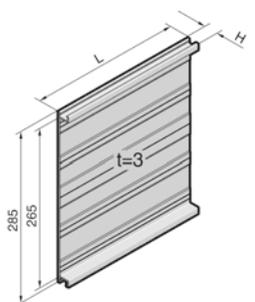
RiLine 附件：叠层铜母线 / 防接触保护

通用支架

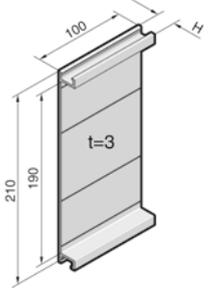
用于固定叠层铜母线	
用于叠层铜母线 mm	5 x 20 x 1 - 10 x 63 x 11)
型号 SV	3079.000

1) 铜片数目 x 铜片宽度 x 铜片厚度

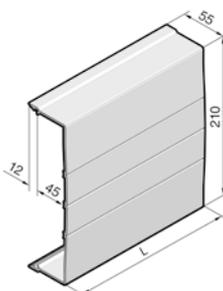
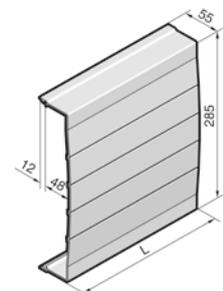
底部槽型件

用于 60 mm 母线系统 认证： UL US LISTED E191125						
用于 RiLine 母线系统	3 极		4 极			
	扁平母线	PLS 800	PLS 1600	扁平母线	PLS 1600 PLUS	
高度 (H) mm	19.5	32	43	19.5	43	
	型号 SV			型号 SV		
长度 (L) mm	500	9340.100 (UL)	9341.100 (UL)	9342.100 (UL)	-	
	700	9340.110 (UL)	9341.110 (UL)	9342.110 (UL)	-	
	900	9340.120 (UL)	9341.120 (UL)	9342.120 (UL)	-	
	1100	9340.130 (UL)	9341.130 (UL)	9342.130 (UL)	9340.134 (UL)	9342.134 (UL)
	2400	9340.170 (UL)	9341.170 (UL)	9342.170 (UL)	-	-

底部槽型件的中间件

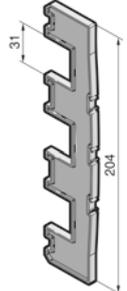
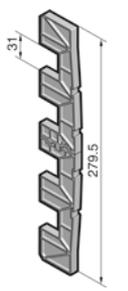
用于 60 mm 母线系统 认证： UL US LISTED E191125			
用于 RiLine 母线系统	3 极		
	扁平母线	PLS 800	PLS 1600
高度 (H) mm	19.5	32	43
型号 SV	9340.140 (UL)	9341.140 (UL)	9342.140 (UL)

盖板

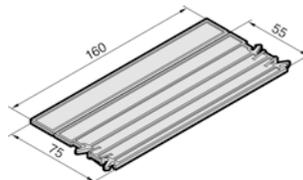
用于 60 mm 母线系统 说明: - 在盖板前面有负荷的情况下要求用支承遮板进行加固 认证: c  US LISTED E191125					
用于 RiLine 母线系统	3 极			4 极	
	扁平母线	PLS 800	PLS 1600	扁平母线	PLS 1600 PLUS
长度 (L) mm	型号 SV			型号 SV	
700	9340.200 			-	
1100	9340.210 			9340.214 	

支承遮板

用于盖板

用于 60 mm 母线系统 认证: c  US LISTED E191125					
用于 RiLine 母线系统	3 极			4 极	
	扁平母线	PLS 800	PLS 1600	扁平母线	PLS 1600 PLUS
型号 SV	9340.220 			9340.224 	

隔档

用于 60 mm 母线系统 认证: c  US LISTED E191125	
型号 SV	9340.230 