



**SV 9340.310, .320, .340, .350, .370,
SV 9340.380, .390, .400, .410, .430,
SV 9340.450, .460, .470, .700, .710,
SV 9340.720, .730, .740, .750, .760,
SV 9340.770, .780, .790**



1 SV OM-Adapter
60 mm Schienenmittenabstand

1 SV OM-Adaptor
60 mm busbar centre distance

1 SV OM-Adaptateur
60 mm d'écartement entre les axes des barres

SV 9340.310, .340, .350, .370, .380, .390

Suitable for use on a circuit capable of delivering not more than 50 kA SCCR symmetrical amperes, 600 volts maximum.

When protected by K5 Class Fuses.

When protected by a circuit breaker having an interrupting rating not less than 50 kA SCCR symmetrical amperes, 600 volts maximum.

SV 9340.410, .430, .450, .460, .470, .700, .710, .720, .730

Suitable for use on a circuit capable of delivering not more than 30 kA SCCR symmetrical amperes, 600 volts maximum.


When protected by K5 Class Fuses.

When protected by a circuit breaker having an interrupting rating not less than 30 kA SCCR symmetrical amperes, 600 volts maximum.




Zeichnungs-Nr. / No. of dwg.:
Versandbeutel-Nr. / No. of accessory bag: **A3983206 SV72**

Lieferanten-Nr. /
No. of supplier:

Montage / mounting

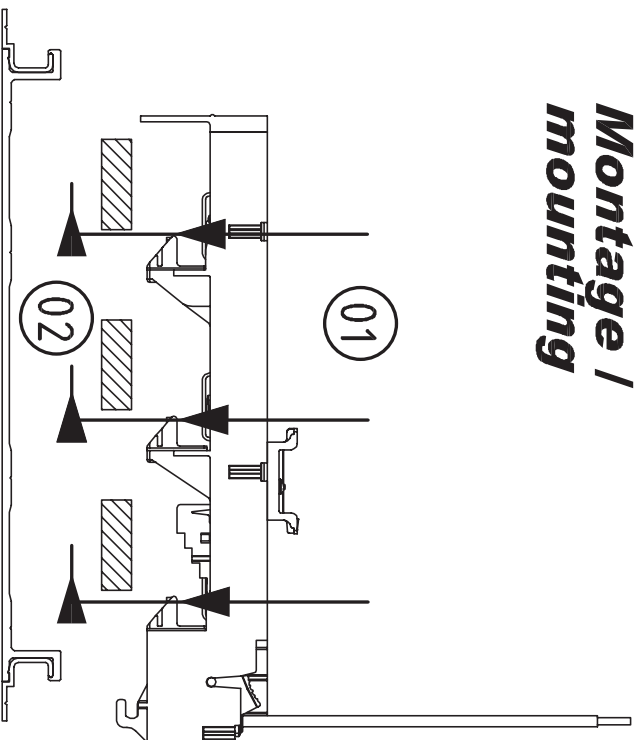

Demontage / dismounting

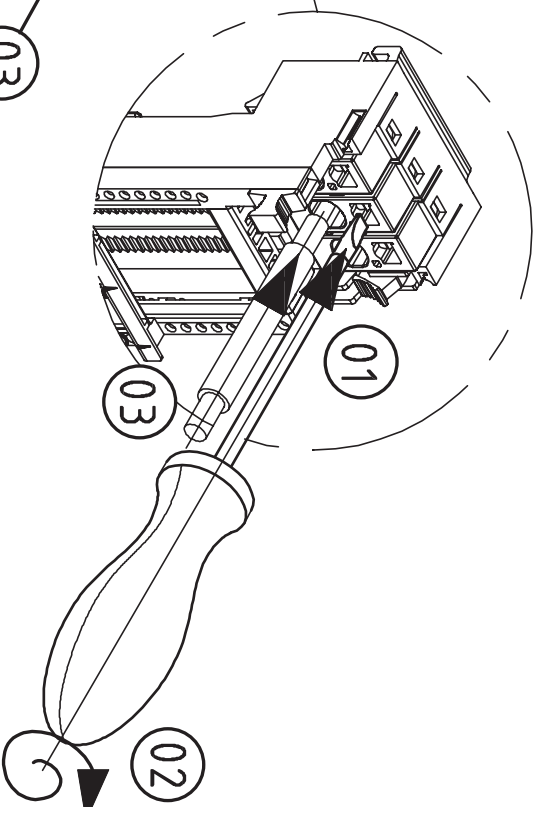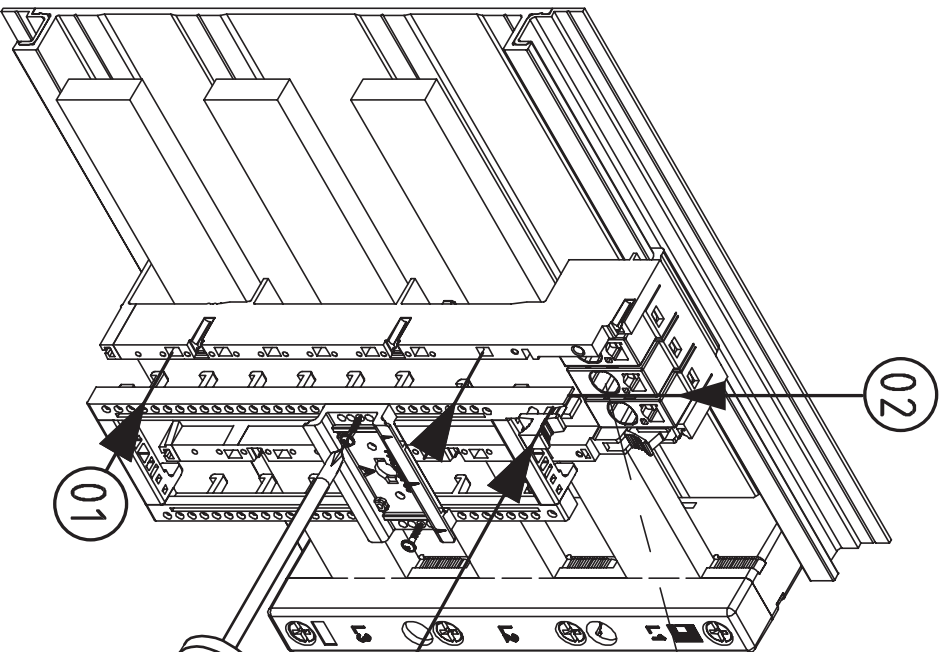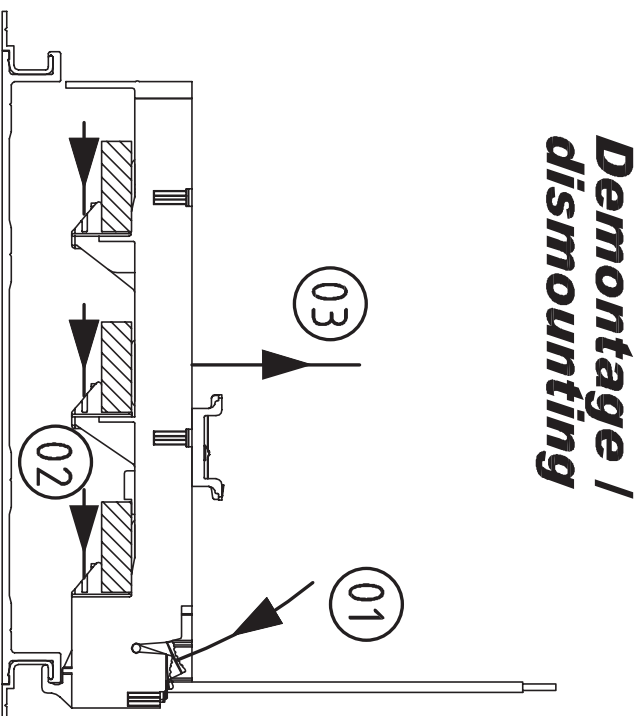

0,5 - 0,7 Nm

