



Serverschränke TE 7000

Handbuch 33, Seite 117


Vorderansicht

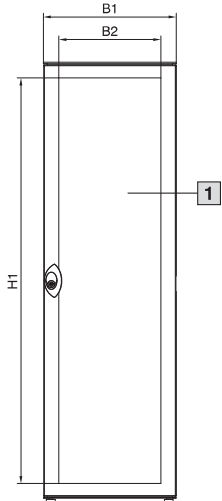


Seitenansicht

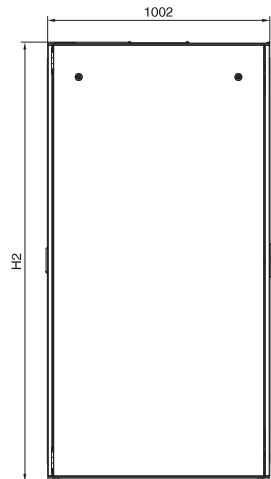


Vorderansicht ohne Tür

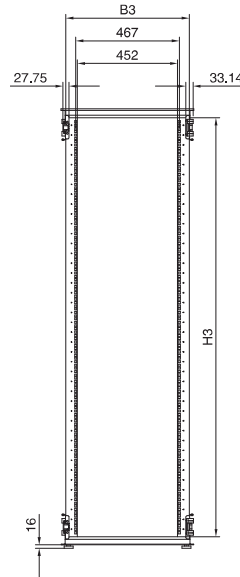

Seitenansicht ohne Seitenwand

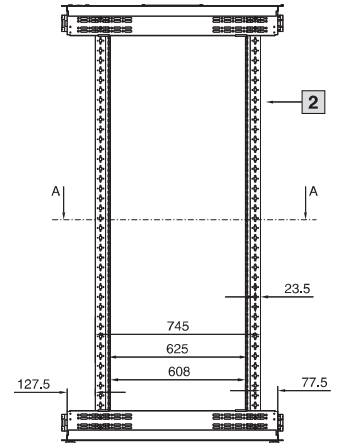


Draufsicht

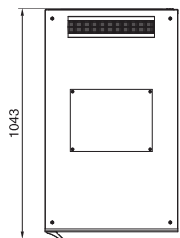


- 1** Gelochter Bereich
- 2** Vorne
- 3** Öffnungsmaß 240 x 340 mm

Draufsicht ohne Tür

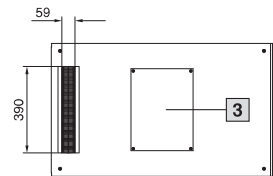

Schnitt A - A

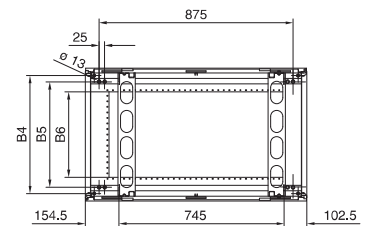

Best.-Nr. DK	HE	Breitenmaße mm						Höhenmaße mm		
		B1	B2	B3	B4	B5	B6	H1	H2	H3
7000.875	21	599	459,6	557	532	475	385	1025	1182	1090
7000.882	42	599	459,6	557	532	475	385	1830	1982	1890
7000.885	42	599	459,6	557	532	475	385	1830	1982	1890
7000.892	42	799	661,7	757	732	675	585	1830	1982	1890
7000.895	42	799	661,7	757	732	675	585	1830	1982	1890