


Schaltschränke

Kleingehäuse


Bus-Gehäuse BG

Handbuch 33, Seite 39


BG 1583.520, BG 1584.520, BG 1585.520, BG 1586.520

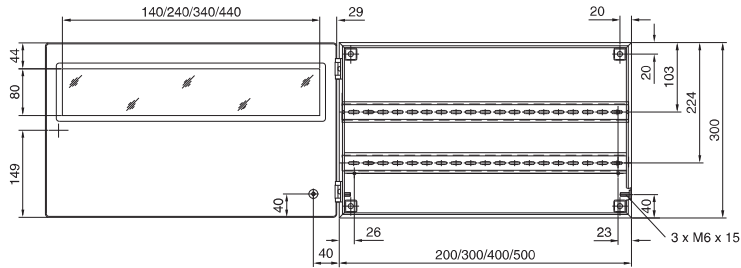


BG 1583.520

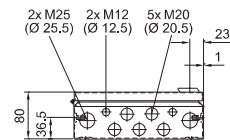


BG 1584.520

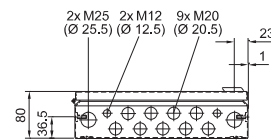

BG 1585.520

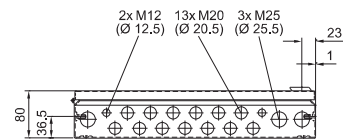


BG 1586.520

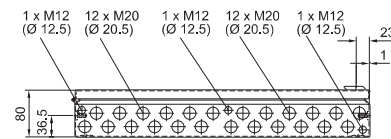


Handbuch 33, Seite 40


BG 1605.520, BG 1606.520

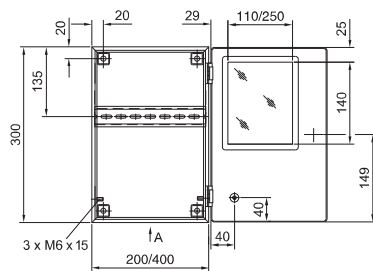

BG 1605.520


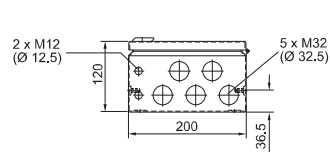


BG 1606.520

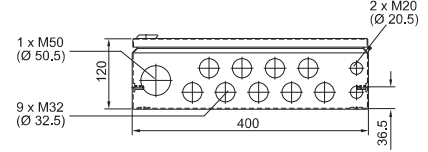

Handbuch 33, Seite 40

BG 1558.510, BG 1559.510

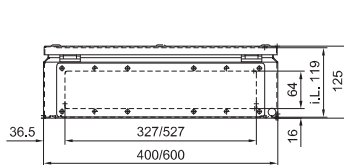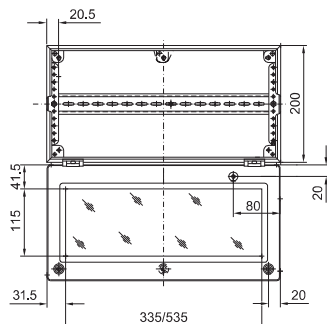


Bus-Gehäuse BG

Handbuch 33, Seite 40


Best.-Nr. BG	Abmessungen mm					Sichtscheibenhöhen mm		Flanschplatten- Öffnung i.L. x i.L. ¹⁾ mm
	B	H	T	F1	G1	H1	H2	
1577.500	400	300	155	385	275	-	-	327 x 97
1577.520						115	92	
1577.530						190	42	
1577.550						115	92	
1577.560						190	42	
1577.450						155	92	
1578.500	600	300	155	585	275	-	-	527 x 97
1578.520						115	92	
1578.530						190	42	
1578.550						115	92	
1578.560						190	42	
1578.450						155	92	
1579.500	800	300	155	785	275	-	-	327 x 97 (2 x)
1579.520						115	92	
1579.530						190	42	
1579.550						115	92	
1579.560						190	42	
1579.450						155	92	

¹⁾ Flanschplatten umlaufend 14 mm größer.

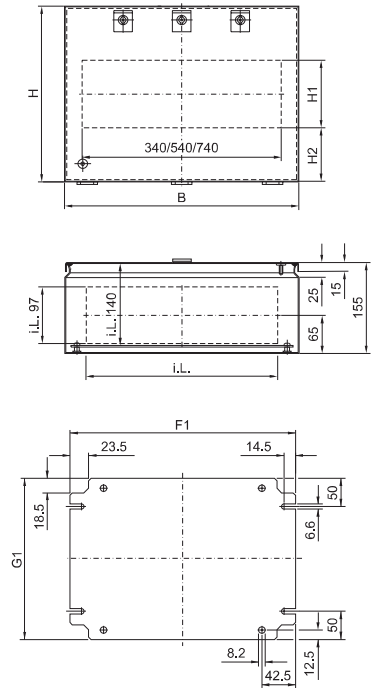

Handbuch 33, Seite 41

BG 1611.510

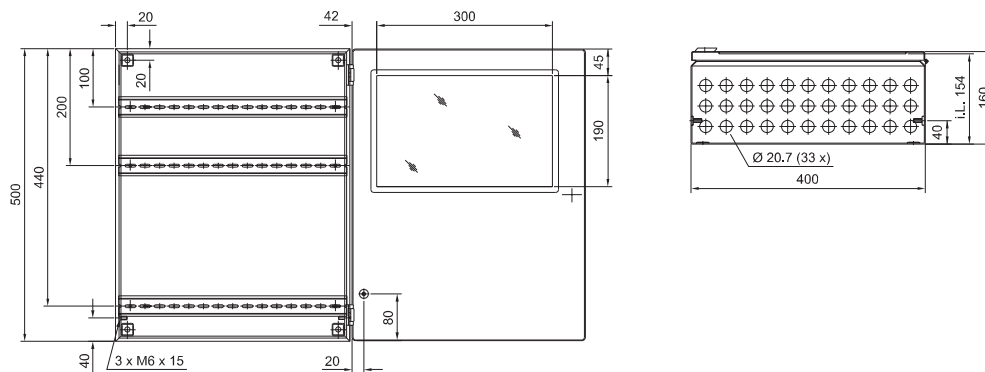

Handbuch 33, Seite 41

BG 1609.510

