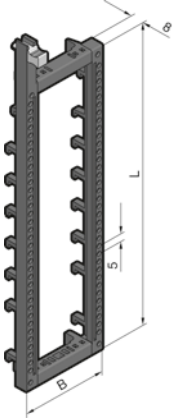


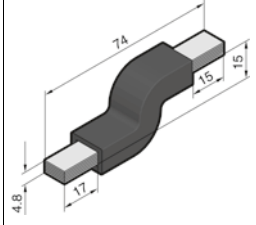
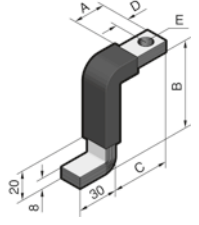
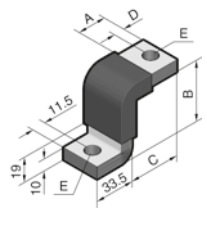
Tragrahmen

Handbuch 33, Seite 320

Für OM-Adapter und OM-Träger				
Breite (B) mm	45	45	55	55
Länge (L) mm	170	237	170	237
Best.-Nr. SV	9341.800	9341.820	9341.830	9341.850

Anschlusswinkel

Handbuch 33, Seite 322

Für CB-Geräteadapter												
Abmessungen ¹⁾ mm	6 x 9 x 0,8				10 x 15,5 x 0,8				10 x 32 x 1			
A mm	—				26	19	23	19	26	29	28	—
B mm	—				65	66	71	67	51	57	62	—
C mm	—				43	36	40	36	62	46	38	—
D mm	—				9	10	9	7	9	12	14	—
E mm	—				Ø 11	Ø 11	Ø 11	Ø 8	Ø 12	Ø 12	Ø 12	—
Best.-Nr. SV	9342.570				9342.660	9342.670	9342.680	9342.690	9342.770	9342.780	9342.790	—

¹⁾ Anzahl der Lamellen x Lamellenbreite x Lamellendicke.