



3.1

IS5

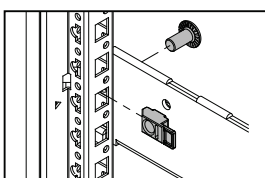

2x M8x16

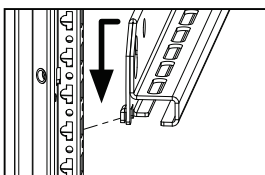


M8x16 M = 12 Nm / 106 in-lbs

3.2

5000 N
max.Transport
2500 N
max.

5x M5x12

TX30

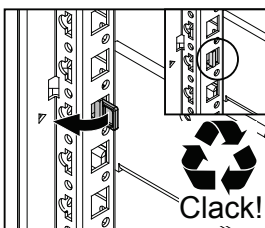

M5x12 M = 5 Nm / 44 in-lbs

4.1

5000 N
max.Transport
2500 N
max.

2x M8x16

IS5



TX30



5x M5x12

M5x12 M = 5 Nm / 44 in-lbs

M8x16 M = 12 Nm / 106 in-lbs

QR-Code
gemäß
RIINT-00009


www.rittal.com

SV

9683.326

9683.328

2x

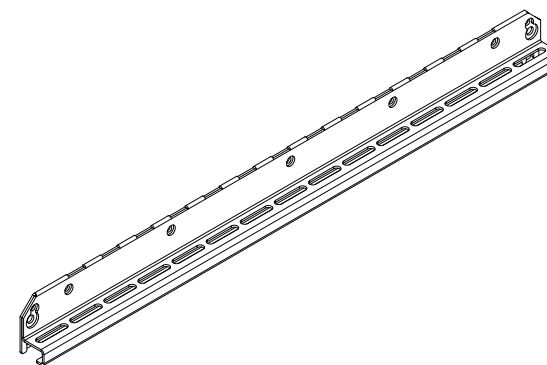

14x


M5x12

4x



M8x16

4x

M8

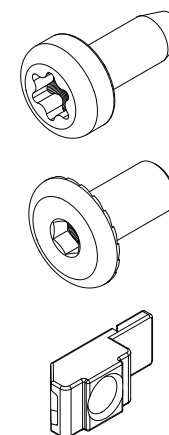Dok.-Nr. / No of doc.: D-0000-00001639-02
Versandbeutel-Nr. / No. of accessory bag: 373754Country of origin:
Lieferanten-Nr. / No. of supplier:RITTAL GmbH & Co. KG, Auf dem Stuetzelberg, 35745 Herborn
RITTAL Limited, Braithwell Way, Hellaby, Rotherham, S66 8QY, UK

1.1

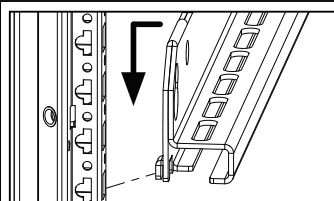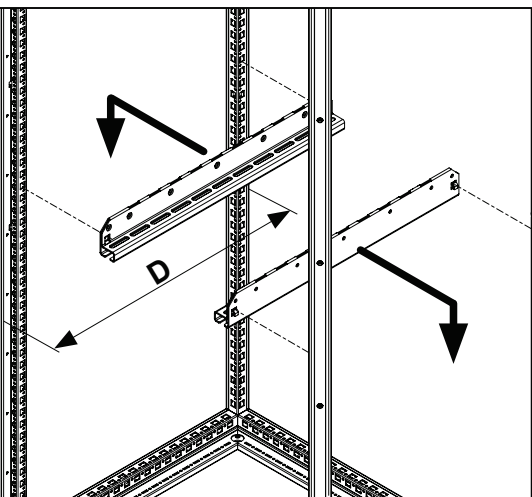


D [mm]	Best.-Nr. Model No. Référence
600	9683.326
800	9683.328

1.2a



3000 N
max.

Transport
1500 N
max.

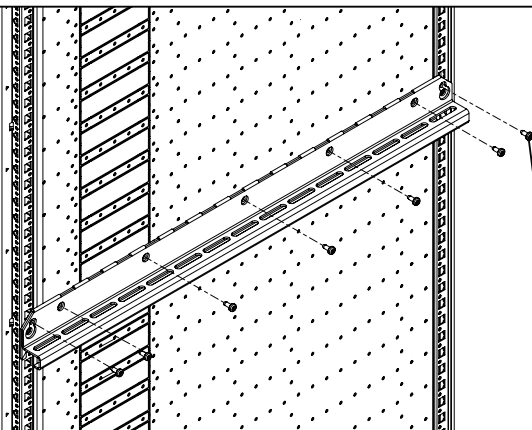

7x M5x12

TX30




M5x12 M = 5 Nm / 44 in-lbs

1.2b



3000 N
max.

Transport
1500 N
max.

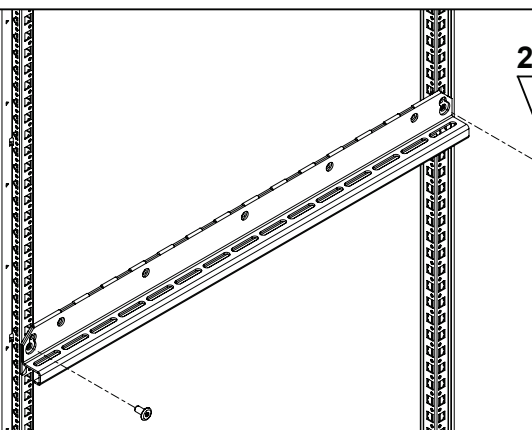


2x M8x16

IS5



M8x16 M = 12 Nm / 106 in-lbs

2.1

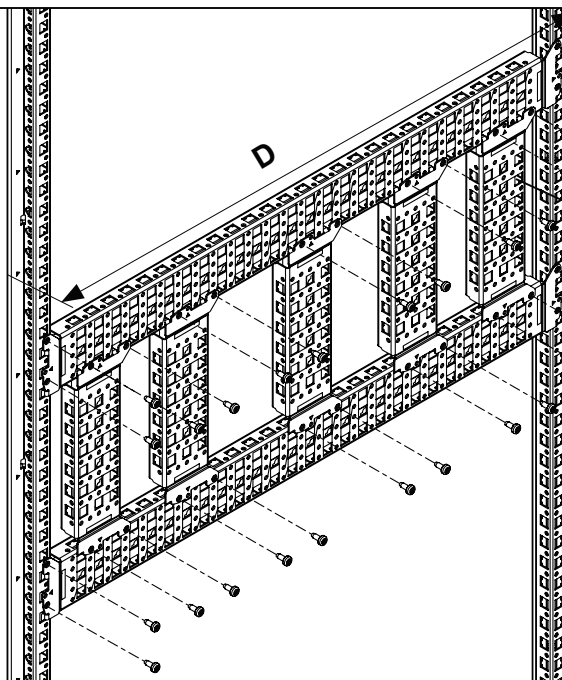

M5x12

8617.100

TX30



D [mm]	Best.-Nr. Model No. Référence
600	8617.130
800	8617.140


M5x12 M = 5 Nm / 44 in-lbs

2.2



3000 N
max.

Transport
1500 N
max.

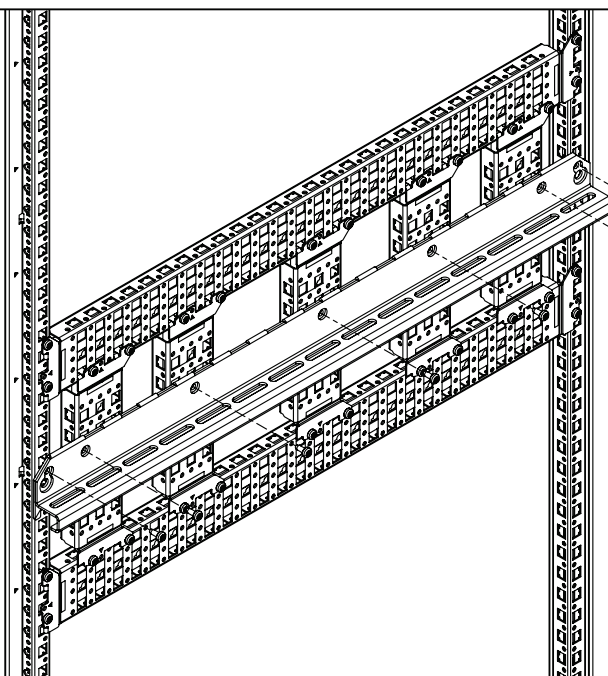

TX30



7x M5x12

M5x12 M = 5 Nm / 44 in-lbs