

System accessories


Cable management 482.6 mm (19")

Cable duct


for VX IT, Data Rack, TX CableNet

DK 5302.051, DK 5302.052, DK 5302.053


Top view, closed

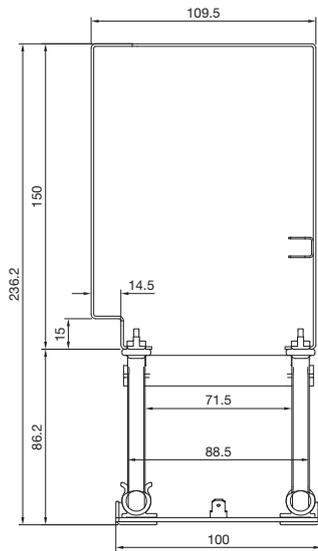

Top view, open

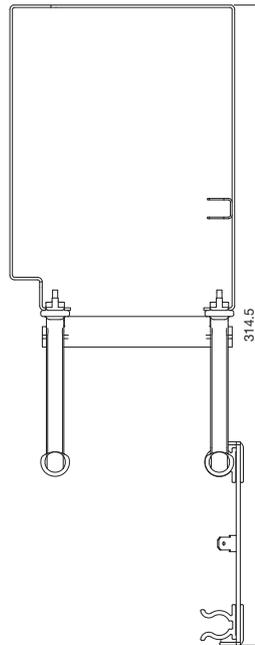

Detail A

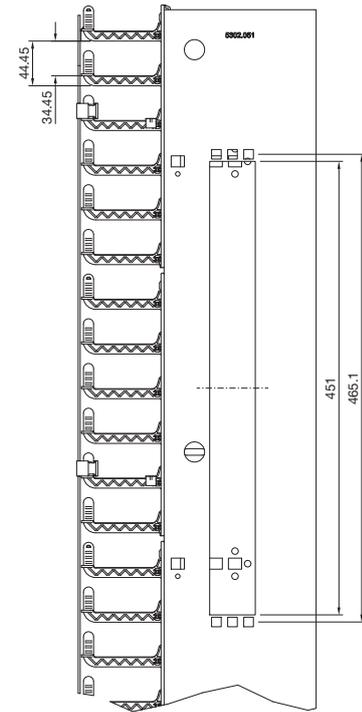

Model No. DK	Height cable duct mm	Supported U	Enclosure system	Max. height of enclosure U/mm	Enclosure configuration with 19" components
5302.051	1699	38	VX IT	38/1800	482.6 mm (19") cross member
	1699	38	Data Rack	40/1900	482.6 mm (19") mounting frame
	1699	38	TX CableNet	42/2000	482.6 mm (19") mounting angles
5302.052	1872	42	VX IT	42/2000	482.6 mm (19") cross member/depth stays
	1872	42	Data Rack	45/2122	482.6 mm (19") mounting frame
	1872	42	TX CableNet	42/2000	482.6 mm (19") mounting angles
5302.053	2099	47	VX IT	47/2200	482.6 mm (19") cross member

Cable duct


for VX IT, Data Rack, TX CableNet

DK 5302.051


Rear view




Side view, left

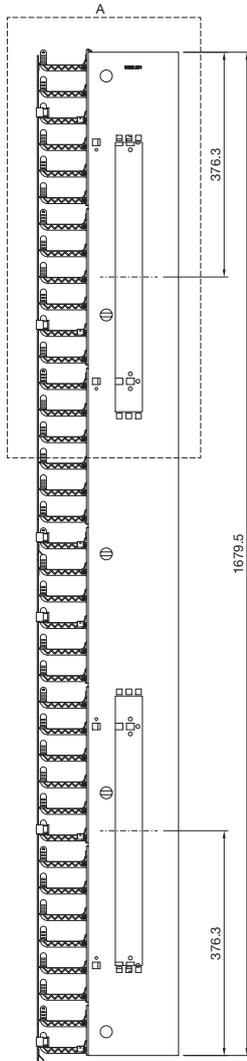


Front view

 

Side view, right

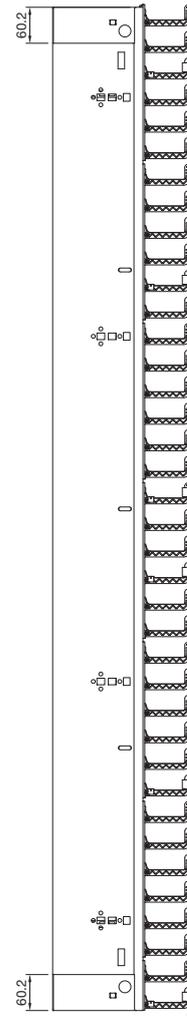

Top view

 

System accessories


Cable management 482.6 mm (19")

Cable duct


for VX IT, Data Rack, TX CableNet

DK 5302.052

 
Rear view




Side view, left

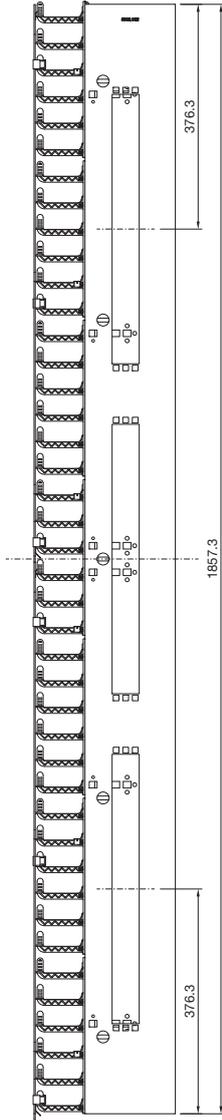


Front view

 

Side view, right

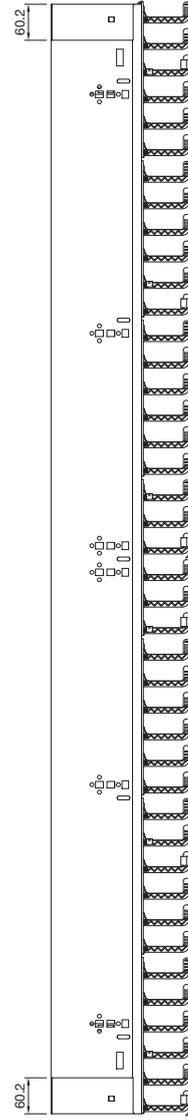

Top view

 


Cable duct


for VX IT, Data Rack, TX CableNet

DK 5302.053

 
Rear view




Side view, left

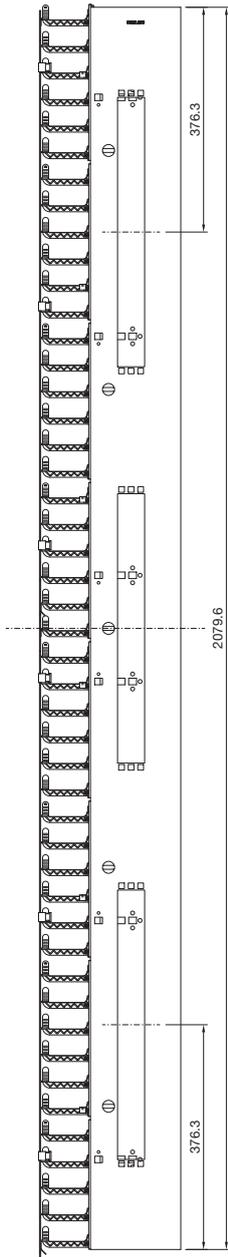

Front view

 

Side view, right

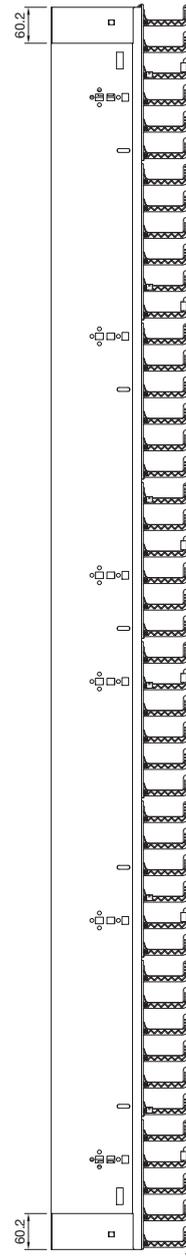

Top view

