


# Rittal – The System.

Faster – better – everywhere.

## ► TS IT Server/Network Enclosures

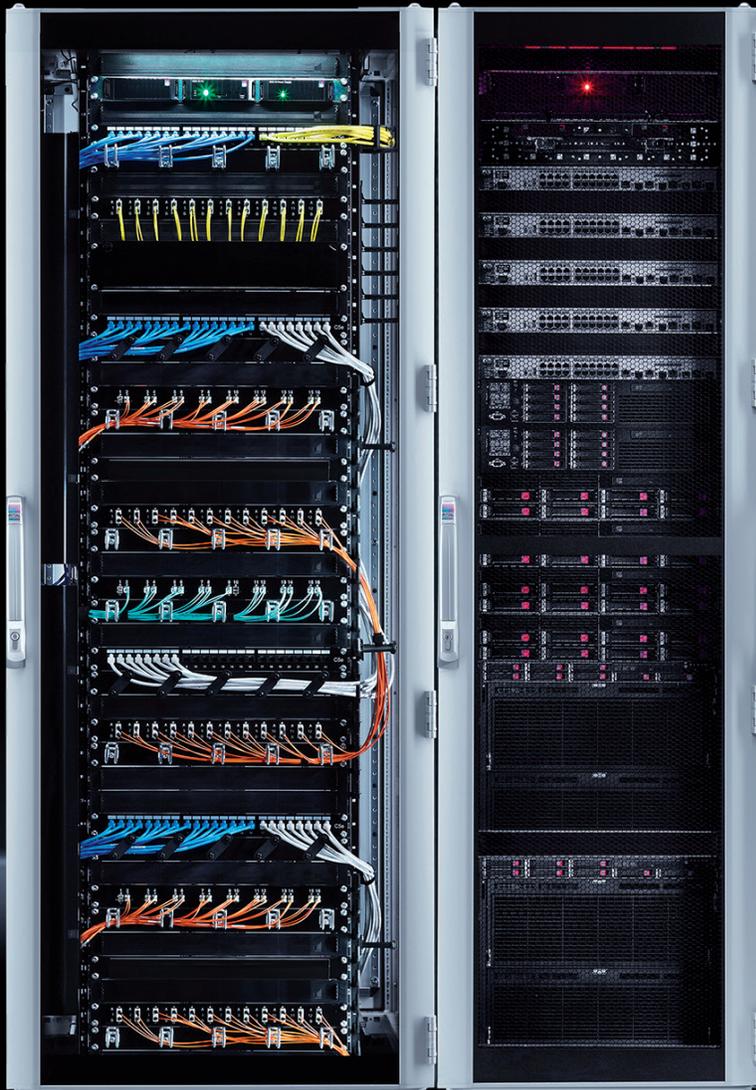

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

[www.rittal.us](http://www.rittal.us)



# Rittal TS IT Enclosures



## Introducing simpliciTy


Data Center Enclosures ■ Ready to Ship ■ Easy to Order

| Number       | Height            | Width       | Depth        | Color      | Sidewalls |
|--------------|-------------------|-------------|--------------|------------|-----------|
| TS42U2442BSW | 42U (80"; 2000mm) | 24" (600mm) | 42" (1050mm) | Black      | Included  |
| TS42U2442B   | 42U (80"; 2000mm) | 24" (600mm) | 42" (1050mm) | Black      |           |
| TS42U2448B   | 42U (80"; 2000mm) | 24" (600mm) | 48" (1200mm) | Black      |           |
| TS42U2448BSW | 42U (80"; 2000mm) | 24" (600mm) | 48" (1200mm) | Black      | Included  |
| TS42U2842B   | 42U (80"; 2000mm) | 28" (700mm) | 42" (1050mm) | Black      |           |
| TS42U2842L   | 42U (80"; 2000mm) | 28" (700mm) | 42" (1050mm) | Light Gray |           |
| TS42U2842BSW | 42U (80"; 2000mm) | 28" (700mm) | 42" (1050mm) | Black      | Included  |
| TS42U2842LSW | 42U (80"; 2000mm) | 28" (700mm) | 42" (1050mm) | Light Gray | Included  |
| TS42U2848BSW | 42U (80"; 2000mm) | 28" (700mm) | 48" (1200mm) | Black      | Included  |
| TS42U2848LSW | 42U (80"; 2000mm) | 28" (700mm) | 48" (1200mm) | Light Gray | Included  |
| TS42U2848B   | 42U (80"; 2000mm) | 28" (700mm) | 48" (1200mm) | Black      |           |
| TS42U2848L   | 42U (80"; 2000mm) | 28" (700mm) | 48" (1200mm) | Light Gray |           |
| TS47U2842LSW | 47U (88"; 2200mm) | 28" (700mm) | 42" (1050mm) | Light Gray | Included  |
| TS47U2842BSW | 47U (88"; 2200mm) | 28" (700mm) | 42" (1050mm) | Black      | Included  |
| TS47U2842B   | 47U (88"; 2200mm) | 28" (700mm) | 42" (1050mm) | Black      |           |
| TS47U2842L   | 47U (88"; 2200mm) | 28" (700mm) | 42" (1050mm) | Light Gray |           |
| TS47U3248BSW | 47U (88"; 2200mm) | 32" (800mm) | 48" (1200mm) | Black      | Included  |
| TS47U3248LSW | 47U (88"; 2200mm) | 32" (800mm) | 48" (1200mm) | Light Gray | Included  |
| TS47U3248B   | 47U (88"; 2200mm) | 32" (800mm) | 48" (1200mm) | Black      |           |
| TS47U3248L   | 47U (88"; 2200mm) | 32" (800mm) | 48" (1200mm) | Light Gray |           |

Rittal's simpliciTy enclosures are ready to deploy with our most popular accessories installed:

- **Integrated Enclosure and Components** designed for the most demanding data center
- **Perforated Single Front and Split Rear Doors**
- **Roof** with brush baffled cable access channels
- **Cable Management Wall** for flexible, organized cabling inside the enclosure
- **Dual PDU Mounting** for power redundancy
- **Low Profile Security Handle** with push button locking inserts
- **Casters** for easy and precise movement during installation
- **Leveling Feet** for a secure installation

For more information visit [www.rittal.us/simplicity](http://www.rittal.us/simplicity)

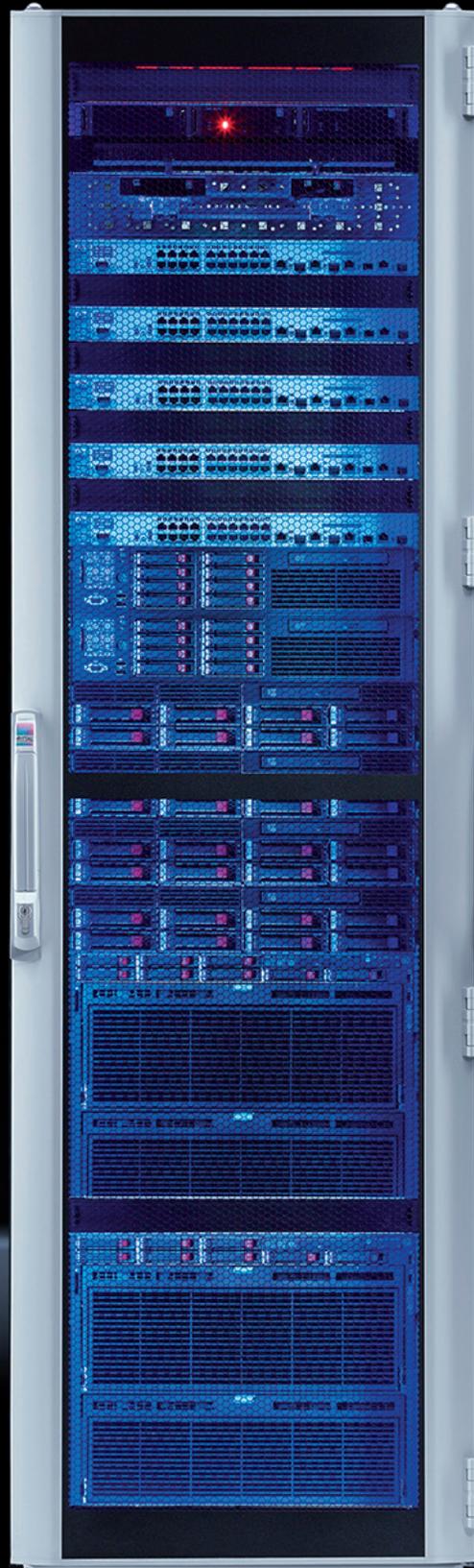

## Choose Rittal For Maximum Flexibility Delivers Maximum Cost-Efficiency

Rittal has redefined the standard in Server and Network enclosures with the TS IT modular system, featuring tool-less, snap-in installation technology that improves operating efficiency while reducing costs. Easy to deploy and providing a stable and secure installation environment for IT equipment, the TS IT system can be easily reconfigured to meet future installation demands. With a streamlined design providing an optimum price/performance ratio, the TS IT system establishes a new standard in functionality, supporting the demanding requirements placed on today's server and network enclosures.

- Most commonly requested dimensions – 24"/28"/32" widths. 40"/42"/48" depths.
- Offset positioning for mounting widths of 19", also 21" and 23" possible with 28" and 32" wide enclosures
- Viewing door or vented door options
- 180-degree hinges on both front and rear doors for unhindered access
- Vertically split rear doors
- Multifunctional roof design for flexible cable routing options
- High load carrying capacity—up to 3,300 lbs
- Engineered solutions cable routing and management
- Seamlessly accommodates all of Rittal's LCP in row cooling options
- Comprehensive range of accessories for power, cable and air flow management
- Tool-free installation of many accessories

## How TS IT Makes IT Fast

- Design flexibility allows integration of high density solutions
- Integrated design process ensures compatibility across different configurations
- Snap-in technology allows for fast assembly of accessory components

The TS IT delivers dimensional flexibility and supports the integration of a variety of IT solutions to support numerous network configurations. To adjust the 19-inch levels, just loosen the quick-release fastening, then slide and lock the mounting angles at the required depth. Lateral offset positioning allows for asymmetrical interior installations and makes it easy to select mounting widths greater than 19 inches.

With the greatest amount of internal useable volume, the TS IT has room for everything. New Ethernet technologies such as 10 GB or 40 GB (with their higher cabling demands) are easily supported. Cabling can be routed via the roof, from the sides or from the base.

## How TS IT Makes IT Simple

- High load carrying capacity—up to 3,300 lbs
- Intelligent cable management system
- Extensive range of accessories

The TS IT can support up to 3,300 lbs. without any additional screw joints, a capability made possible by our depth stays that transmit the load to the enclosure's frame. The quick-release fasteners simplify initial assembly, any subsequent modifications, and installation of accessory components.

For added safety, the tool-free installation accessories (cable duct, air baffle plate, cable route and floor holder) have integrated holes to allow optional screw fastening. Slide rails, component shelves, telescopic slides and more simply snap into the rear sections and hook into the front EIA rail sections.





**Choose the Best:**  
Accessories deliver more  
custom design options

## System Accessories



### Viewing and Vented Doors

Choose glass for rack climate control or vented for room climate control.



### Base/Plinth System

Flexible base/plinth system for practically every application.



### Airflow Options

Baffles, gland plates and blanking panels designed to provide optimal air flow in an enclosure.



### Security Options

Flexible access, either 3-digit code keyless or master control functionality.



### Cable Management

Ducts, fingers, cable management panels, cable management walls and D-rings keep cables organized.



### Shelving and System Chassis

Install heavy equipment securely within a 19-inch rack.

| TS IT Enclosure with Perforated Front/Rear Doors          |  |  |                       |                      |                      |
|---|--|--|-----------------------|----------------------|----------------------|
| Part No.<br>Black   | Part No.<br>Light Gray                                     | U  | Height inches<br>(mm) | Width inches<br>(mm) | Depth inches<br>(mm) |
| 5504.210  | 5504.110   | 24   | 48 (1200)             | 32 (800)             | 40 (1000)            |
| 5508.210  | 5508.110   | 42   | 80 (2000)             | 24 (600)             | 40 (1000)            |
| 5509.210  | 5509.110   | 42   | 80 (2000)             | 32 (800)             | 40 (1000)            |
| 5521.210  | -  | 42   | 80 (2000)             | 24 (600)             | 41 (1050)            |
| 9972.000  | 9972.001   | 42   | 80 (2000)             | 28 (700)             | 41 (1050)            |
| 5522.210  | -  | 42   | 80 (2000)             | 32 (800)             | 41 (1050)            |
| 5510.210  | 5510.110   | 42   | 80 (2000)             | 24 (600)             | 48 (1200)            |
| 9972.002  | 9972.003   | 42   | 80 (2000)             | 28 (700)             | 48 (1200)            |
| 5511.210  | 5511.110   | 42   | 80 (2000)             | 32 (800)             | 48 (1200)            |
| 5513.210  | 5513.110   | 47   | 88 (2200)             | 24 (600)             | 40 (1000)            |
| 5514.210  | 5514.110   | 47   | 88 (2200)             | 32 (800)             | 40 (1000)            |
| 5523.210  | -  | 47   | 88 (2200)             | 24 (600)             | 41 (1050)            |
| 5524.210  | -  | 47   | 88 (2200)             | 32 (800)             | 41 (1050)            |
| 9972.004  | 9972.005   | 47   | 88 (2200)             | 28 (700)             | 41 (1050)            |
| 5515.210  | 5515.110   | 47   | 88 (2200)             | 24 (600)             | 48 (1200)            |
| 9972.006  | 9972.007   | 47   | 88 (2200)             | 28 (700)             | 48 (1200)            |
| 5516.210  | 5516.110   | 47   | 88 (2200)             | 32 (800)             | 48 (1200)            |
| TS IT Enclosure with Viewing Front Door – Solid Rear Door |  |  |                       |                      |                      |
| Part No.<br>Black   | Part No.<br>Light Gray                                     | U  | Height inches<br>(mm) | Width inches (mm)    | Depth inches<br>(mm) |
| 5503.220  | 5503.120   | 24   | 48 (1200)             | 32 (800)             | 32 (800)             |
| 5504.220  | 5504.120   | 24   | 48 (1200)             | 32 (800)             | 40 (1000)            |
| 5505.220  | 5505.120   | 38   | 71 (1800)             | 32 (800)             | 32 (800)             |
| 5506.220  | 5506.120   | 42   | 80 (2000)             | 32 (800)             | 24 (600)             |
| 5507.220  | 5507.120   | 42   | 80 (2000)             | 32 (800)             | 32 (800)             |
| 5508.220  | 5508.120   | 42   | 80 (2000)             | 24 (600)             | 40 (1000)            |
| 5509.220  | 5509.120   | 42   | 80 (2000)             | 32 (800)             | 40 (1000)            |
| 5510.220  | 5510.120   | 42   | 80 (2000)             | 24 (600)             | 48 (1200)            |
| 5511.220  | 5511.120   | 42   | 80 (2000)             | 32 (800)             | 48 (1200)            |
| 5512.220  | 5512.120   | 47   | 88 (2200)             | 32 (800)             | 32 (800)             |
| Airflow Management  |  |  |                       |                      |                      |
| Part No.  | Description  |  |                       |                      | Packs of             |
| 5501.805  | Air baffle plate 24" x 80" (600 x 2000 mm)                 |  |                       |                      | 1 set                |
| 9972.925  | Air baffle plate 28" x 80" (700 x 2000 mm)                 |  |                       |                      | 1 set                |
| 5501.815  | Air baffle plate 32" x 80" (800 x 2000 mm)                 |  |                       |                      | 1 set                |
| 5501.825  | Air baffle plate 24" x 88" (600 x 2200 mm)                 |  |                       |                      | 1 set                |
| 9972.926  | Air baffle plate 28" x 88" (700 x 2200 mm)                 |  |                       |                      | 1 set                |
| 5501.835  | Air baffle plate 32" x 88" (800 x 2200 mm)                 |  |                       |                      | 1 set                |
| 9960.676  | 1U Blanking panel (sand texture black), plastic            |  |                       |                      | 12                   |
| 9970.016  | 1U Blanking panel (sand texture black), metal              |  |                       |                      | 10                   |
| 9970.017  | 3U Blanking panel (sand texture black), metal              |  |                       |                      | 5                    |
| Shelves   |  |  |                       |                      |                      |
| Part No.  | Description  |  |                       |                      | Packs of             |
| 5501.615  | Component shelf, 2 U, static installation (250 mm)         |  |                       |                      | 1 set                |
| 5501.625  | Component shelf, 2 U, static installation (400 mm)         |  |                       |                      | 1 set                |
| 5501.655  | Component shelf, 0.5 U, static installation (400 - 600 mm) |  |                       |                      | 1 set                |
| 5501.665  | Component shelf, 0.5 U static installation (600 - 900 mm)  |  |                       |                      | 1 set                |
| 5501.695  | Component shelf, 1 U static installation (400 - 600 mm)    |  |                       |                      | 1 set                |
| 5501.705  | Component shelf, 1 U static installation (600 - 900 mm)    |  |                       |                      | 1 set                |
| 5501.675  | Component shelf, 1 U pull-out, 500 mm                      |  |                       |                      | 1 set                |
| 5501.685  | Component shelf, 1U pull-out 700 mm                        |  |                       |                      | 1 set                |
| 5501.715  | Component shelf, 1.5 U pull-out 500 mm                     |  |                       |                      | 1 set                |
| 5501.725  | Component shelf, 1.5 U pull-out 700 mm                     |  |                       |                      | 1 set                |
| Sidewalls   |  |  |                       |                      |                      |
| Part No.<br>Black   | Part No.<br>Light Gray                                     | Description                                  |                       |                      | Packs of             |
| 5501.005  | 5501.000   | Side panel divided 71 x 32" (1800 x 800 mm)  |                       |                      | 1                    |
| 5501.015  | 5501.010   | Side panel divided 80 x 24" (2000 x 600 mm)  |                       |                      | 1                    |
| 5501.025  | 5501.020   | Side panel divided 80 x 32" (2000 x 800 mm)  |                       |                      | 1                    |
| 5501.035  | 5501.030   | Side panel divided 80 x 40" (2000 x 1000 mm) |                       |                      | 1                    |
| 5501.045  | 5501.040   | Side panel divided 80 x 48" (2000 x 1200 mm) |                       |                      | 1                    |
| 5501.055  | 5501.050   | Side panel divided 88 x 32" (2200 x 800 mm)  |                       |                      | 1                    |
| 5501.065  | 5501.060   | Side panel divided 88 x 40" (2200 x 1000 mm) |                       |                      | 1                    |
| 5501.075  | 5501.070   | Side panel divided 88 x 48" (2200 x 1200 mm) |                       |                      | 1                    |
| 5501.095  | -  | Side panel divided 80 x 41" (2000 x 1050 mm) |                       |                      | 1                    |

| Sidewalls (continued)               |   |  |          |
|-------------------------------------|---|--|----------|
| Part No.<br>Black                   | Part No.<br>Light Gray  | Description                                  | Packs of |
| 5501.105                            | -   | Side panel divided 88 x 41" (2200 x 1050 mm) | 1        |
| 9966.010                            | 8175.235  | TS IT Solid SIDE WALLS (1200 H x 800 D)      | 2        |
| 9966.011                            | 8108.235  | TS IT Solid SIDE WALLS (2000 H x 800 D)      | 2        |
| 9966.012                            | 8100.235  | TS IT Solid SIDE WALLS (2000 H x 1000 D)     | 2        |
| 9966.013                            | 9969.309  | TS IT Solid SIDE WALLS (2000 H x 1050 D)     | 2        |
| 9966.014                            | 9969.955  | TS IT Solid SIDE WALLS (2000 H x 1200 D)     | 2        |
| 9966.015                            | 8128.235  | TS IT Solid SIDE WALLS (2200 H x 800 D)      | 2        |
| 9966.016                            | 9968.593  | TS IT Solid SIDE WALLS (2200 H x 1000 D)     | 2        |
| 9966.017                            | 9969.312  | TS IT Solid SIDE WALLS (2200 H x 1050 D)     | 2        |
| 9966.018                            | 9969.957  | TS IT Solid SIDE WALLS (2200 H x 1200 D)     | 2        |
| Partition Walls (Bayed Application) |   |  |          |
| Part No.<br>Black                   | Description   |  | Packs of |
| 9971.042                            | TS IT Partition Wall with Cable openings (2000 H x 1000 D)    |  | 1        |
| 9971.043                            | TS IT Partition Wall with Cable openings (2000 H x 1050 D)    |  | 1        |
| 9971.044                            | TS IT Partition Wall with Cable openings (2000 H x 1200 D)    |  | 1        |
| 9971.046                            | TS IT Partition Wall with Cable openings (2200 H x 1000 D)    |  | 1        |
| 9971.047                            | TS IT Partition Wall with Cable openings (2200 H x 1050 D)    |  | 1        |
| 9971.048                            | TS IT Partition Wall with Cable openings (2200 H x 1200 D)    |  | 1        |
| 9978.378                            | TS IT Partition Wall Solid (2000 H x 1000 D)                  |  | 1        |
| 9978.379                            | TS IT Partition Wall Solid (2000 H x 1050 D)                  |  | 1        |
| 9978.380                            | TS IT Partition Wall Solid (2000 H x 1200 D)                  |  | 1        |
| 9978.382                            | TS IT Partition Wall Solid (2200 H x 1000 D)                  |  | 1        |
| 9978.383                            | TS IT Partition Wall Solid (2200 H x 1050 D)                  |  | 1        |
| 9978.384                            | TS IT Partition Wall Solid (2200 H x 1200 D)                  |  | 1        |
| Cable Management (Internal)         |   |  |          |
| Part No.                            | Description   |  | Packs of |
| 5502.105                            | Cable duct for enclosure height 80" (2000 mm) 32" W only      |  | 1        |
| 5502.145                            | Cable duct for enclosure height 88" (2200 mm) 32" W only      |  | 1        |
| 9972.927                            | Cable duct 69"H (1760 mm) for 28"W (700 mm) or 32" W (800 mm) |  | 1        |
| 9972.912                            | Cable Management Fingers 20U for 42 U (2000 mm H)             |  | 2        |
| 9972.913                            | Cable Management Fingers 22U for 47 U (2200 mm H)             |  | 2        |
| 5502.115                            | Cable finger 6U   |  | 14       |
| 5502.205                            | Cable management panel with 5 steel brackets 1U               |  | 1        |
| 7257.105                            | Cable management panel with 5 steel brackets 2U               |  | 1        |
| 5502.225                            | Cable management panel with plastic cable routing bars 1U     |  | 1        |
| 5502.235                            | Cable management compartment with cutouts 2U                  |  | 1        |
| 5502.245                            | Cable routing channel, open top 1U                            |  | 1        |
| 5502.255                            | Cable entry panel with brush strip opening 1U                 |  | 1        |
| 5502.265                            | Cable entry panel with brush strip opening 2U                 |  | 1        |
| 5502.120                            | Cable route, adjustable height 80 - 88" (2000 - 2200 mm)      |  | 1        |
| 9978.360                            | Cable management wall 42U (700 - 800 mm W) incl. PDU mount    |  | 1        |
| 9978.361                            | Cable management wall 47U (700 - 800 mm W) incl. PDU mount    |  | 1        |
| 5502.155                            | Nylon tape supports   |  | 10       |
| 9969.599                            | Quarter-turn velcro cable fastener 17" (420 mm)               |  | 10       |
| 9969.600                            | Quarter-turn cable collection                                 |  | 10       |
| 9961.780                            | Quarter-turn D-ring, 5 x 3.5" (127 x 88.9 mm)                 |  | 10       |
| 9972.922                            | Quarter-turn D-ring, 3.5 x 1.75" (88.9 x 44.5 mm)             |  | 10       |
| Cable Management (Roof Mounted)     |   |  |          |
| Part No.                            | Description   |  | Packs of |
| 9970.292                            | TS IT 0600W ROOF MT CABLE MGR                                 |  | 1        |
| 9970.293                            | TS IT 0700W ROOF MT CABLE MGR                                 |  | 1        |
| 9970.294                            | TS IT 0800W ROOF MT CABLE MGR                                 |  | 1        |
| 9970.295                            | TS IT 0600W ROOF MT CABLE MGR FOR LADDER                      |  | 1        |
| 9970.296                            | TS IT 0700W ROOF MT CABLE MGR FOR LADDER                      |  | 1        |
| 9970.297                            | TS IT 0800W ROOF MT CABLE MGR FOR LADDER                      |  | 1        |
| 9970.298                            | TS IT END CORNER BRACKETS                                     |  | 1        |
| 9970.260                            | ROOF MOUNT CABLE MANAGER END COVERS                           |  | 1        |
| 9970.270                            | LADDER RACK INSTALLATION BRACKETS                             |  | 1        |
| 9970.271                            | 12IN W X 10FT L LADDER RACK                                   |  | 1        |
| Other Accessories                   |   |  |          |
| Part No.<br>Black                   | Part No.<br>Light Gray  | Description                                  | Packs of |
| 9967.480                            | 9967.483  | Caster Kit Front and Rear 600 W              | 1 Set    |
| 9967.481                            | 9967.484  | Caster Kit Front and Rear 700 W              | 1 Set    |
| 9967.482                            | 9967.485  | Caster Kit Front and Rear 800 W              | 1 Set    |
| 8800.490                            | -   | Baying connectors, external, unpainted       | 6        |

# Rittal – The System.

Faster – better – everywhere.

- Enclosures
- Power Distribution
- Climate Control
- IT Infrastructure
- Software & Services

## Rittal North America LLC

Woodfield Corporate Center  
425 North Martingale Road, Suite 400 • Schaumburg, Illinois 60173 • USA  
Phone: 937-399-0500 • Toll-free: 800-477-4000  
Email: [rittal@rittal.us](mailto:rittal@rittal.us) • Website: [www.rittal.us](http://www.rittal.us)

## Rittal Systems Ltd.

6485 Ordan Drive • Mississauga, Ontario L5T 1X2 • Canada  
Phone: 905-795-0777 • Toll-free: 800-399-0748  
Email: [marketing@rittal.ca](mailto:marketing@rittal.ca) • Website: [www.rittal.ca](http://www.rittal.ca)

## Rittal Mexico

Dr. Roberto Gayol 1219-1B • Col. Del Valle Sur, 03100 • Mexico, D.F.  
Phone: (+52) (55) 5559-5369 • Toll-free: 01 800 8 Rittal (748.825)  
Email: [info@rittal.com.mx](mailto:info@rittal.com.mx) • Website: [www.rittal.com.mx](http://www.rittal.com.mx)

US387 ■ 2/18

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

