


# Rittal – The System.

Faster – better – everywhere.

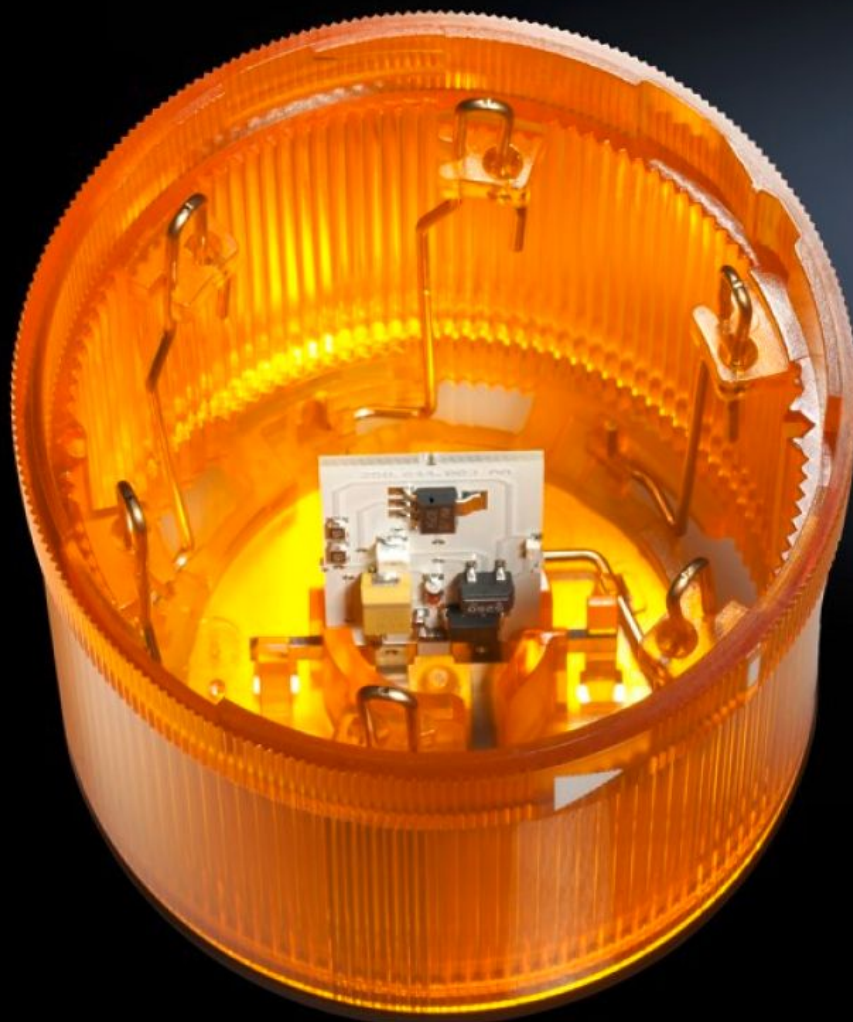

## SG 2372.020

### LED steady light component

State: 31/01/2026 (Source: [rittal.com/au-en](http://rittal.com/au-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SG 2372.020 - LED steady light component for signal pillar, modular

With 360° signal transmission thanks to optimised prism system, number of potential stages = 5 components, with identical voltage.

## Features

|                                                 |                                                                                                                                                                                    |
|-------------------------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Model No.                                       | SG 2372.020                                                                                                                                                                        |
| Design                                          | LED steady light component                                                                                                                                                         |
| Product description                             | With 360° signal transmission thanks to optimised prism system.<br>Number of potential stages = 5 components, with identical voltage.                                              |
| Benefits                                        | Simple assembly and contact via bayonet fastener.<br>Configuration of up to five components with the same voltage.<br>Components are available in a range of colours and voltages. |
| Function principle                              | A modular layout is possible with connection, optical and acoustic components, incandescent lamps and a label panel                                                                |
| Material                                        | Enclosure of polyamide<br>Cap: Transparent polycarbonate                                                                                                                           |
| Colour                                          | Yellow                                                                                                                                                                             |
| Diameter                                        | 70 mm                                                                                                                                                                              |
| Rated impulse withstand voltage, phase to phase | 2500 V AC                                                                                                                                                                          |
| Rated insulation voltage                        | 250 V AC                                                                                                                                                                           |
| Rated current max.                              | 25 mA                                                                                                                                                                              |
| Dimensions                                      | Height: 56 mm                                                                                                                                                                      |
| Protection category to IEC 60 529               | IP 54 if a cover or acoustic component is fitted at the top                                                                                                                        |
| Rated operating voltage                         | 24 V (AC/DC)                                                                                                                                                                       |
| Packs of                                        | 1 pc(s).                                                                                                                                                                           |
| Net weight                                      | 0.08                                                                                                                                                                               |
| Gross weight                                    | 0.089                                                                                                                                                                              |

# Features

|                       |               |
|-----------------------|---------------|
| Customs tariff number | 85311095      |
| EAN                   | 4028177220195 |
| ETIM 9                | EC000232      |
| ETIM 8                | EC000232      |
| ECLASS 8.0            | 27371220      |

# Approvals

|           |                          |
|-----------|--------------------------|
| Approvals | UL + C-UL (listed)<br>UR |
|-----------|--------------------------|