
 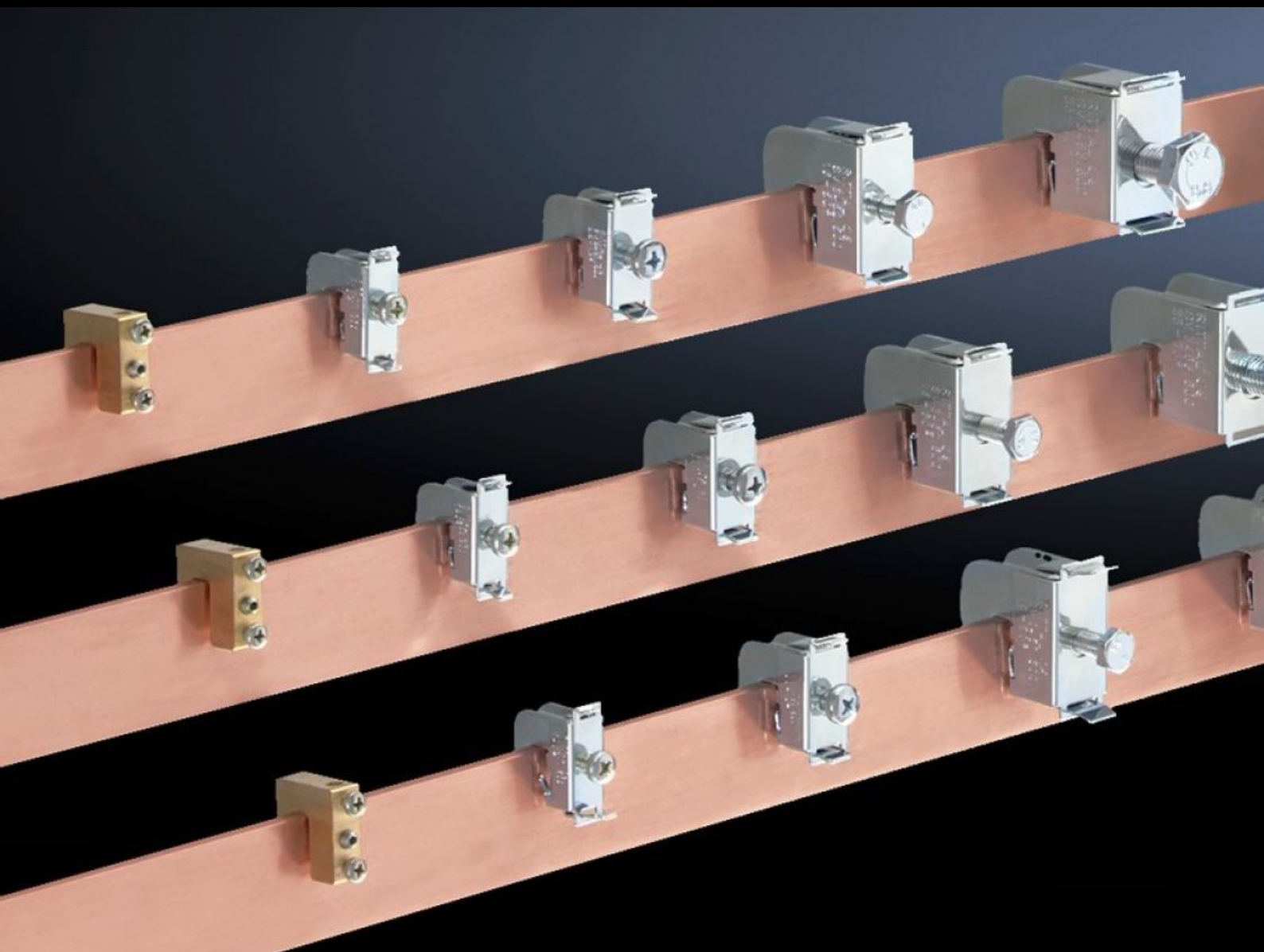


# Rittal – The System.

Faster – better – everywhere.



## SV 3450.500 Conductor connection clamp

State: 16/05/2024 (Source: [rittal.com/au-en](https://www.rittal.com/au-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SV 3450.500 - Conductor connection clamp

For connecting round conductors and laminated copper bars.

## Features

Model No.	SV 3450.500
Product description	For connecting round conductors and laminated copper bars.
Material	Sheet steel
Surface finish	Zinc-plated, passivated
Note	Wire end ferrules should be used with fine wire conductors
Connection for round conductor cross-sections	1 - 4 mm <sup>2</sup>
For bar thickness	5 mm
Packs of	15 pc(s).
Weight/pack	0.27 kg
Customs tariff number	85369010
EAN	4028177042674
ETIM 7.0	EC000001
ECLASS 8.0	27141146

## Approvals

Approvals	C-UR UR + C-UR (recognized)
Explanations	Declaration of conformity Declaration of conformity UK

# Tender text

SV conductor connection clamps  
for E-CU busbars and Rittal PLS.

for bar thickness: 5 mm

Connection of round conductors: 1 - 4 mm<sup>2</sup>

Wire end ferrules should be used with fine wire  
conductors

Tightening torque

Conductor connection clamp: 2 Nm

Material: sheet steel, zinc plated, passivated