


# Rittal – The System.

Faster – better – everywhere.

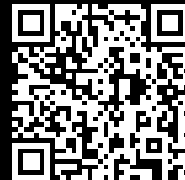

## DK 7246.400 Adaptor, 3 U

State: 12/07/2025 (Source: [rittal.com/au-en](http://rittal.com/au-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7246.400 - Adaptor, 3 U Depth offset 100 mm

Used to recess 482.6 mm (19") mounting of equipment inside enclosures with 482.6 mm (19") installation in the foremost position, such as server or electronic enclosures.



## Features

|                               |   |
|-------------------------------|---|
| Model No.                     | DK 7246.400   |
| Product description           | This adaptor is used to recess 482.6 mm (19") mounting of equipment inside enclosures with 482.6 mm (19") installation in the foremost position, such as server or electronic enclosures. In this way, sufficient space can be gained in front of the mounting equipment to integrate patch panels or switches, whilst at the same time exploiting the maximum enclosure depth. |
| Material                      | Sheet steel   |
| Surface finish                | Zinc-plated   |
| Supply includes               | Assembly parts  |
| Units                         | 3 U   |
| Installation dimensions       | Installation depth for components: 482.6 mm<br>Installation width for components: 19"   |
| Packs of                      | 2 pc(s).  |
| Net weight                    | 0.34  |
| Gross weight                  | 0.37  |
| PCF per pack (cradle-to-gate) | 1.4 kg CO2 eq (Cat B)   |
| Note on PCF category          | Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared  |

## Features

|                       |               |
|-----------------------|---------------|
| Customs tariff number | 73269098      |
| EAN                   | 4028177389830 |
| ETIM 9                | EC002625      |
| ECLASS 8.0            | 27189234      |

## Tender text

482.6 mm (19") adaptor, 3 U, 100 mm depth offset  
Material: Sheet steel, zinc-plated, passivated