


Rittal – The System.

Faster – better – everywhere.

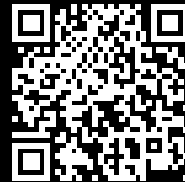

DK 7502.136

QuickBox, 482.6 mm (19")

State: 7/12/2025 (Source: rittal.com/au-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7502.136 - QuickBox, 482.6 mm (19")

Wall-mounted enclosure with removable cover for simple installation and horizontal 482.6 mm (19") level. Status monitoring via viewing window.

Features

Model No.	DK 7502.136
Design	With sheet steel door
Product description	Wall-mounted enclosure with removable cover for perfect handling during installation and maintenance.
Material	Wall mounting plate with mounting brackets: Sheet steel, 2.0 mm Enclosure cover: Sheet steel, 1.0 mm Door: Sheet steel door or glazed door with sheet steel frame and single-pane safety glass, 3 mm
Surface finish	Enclosure: Powder-coated
Colour	RAL 7035
Supply includes	Wall section: with pre-configured mounting brackets, brush strip for cable entry at the bottom/top, cable clamp rail, 482.6 mm (19") mounting angles, fully depth adjustable Enclosure cover: Base and cover tray with vent slots, brush strip for cable entry at the top/bottom, 2 side security locks, sheet steel door or glazed door with security lock 12321, version with Ergoform-S lock system, may optionally be retrofitted with semi-cylinder.
Units	12 U
Dimensions	Width: 600 mm Height: 628 mm Depth: 600 mm
Installation depth	547 mm
Depth of wall section	621 mm
Width wall section	595 mm
Basic material	Sheet steel
Packs of	1 pc(s).

Features

Net weight	32.775
Gross weight	34.5
Customs tariff number	94032080
EAN	4028177201408
E-Number Sweden	E7239631
ECLASS 8.0	27180208