


# Rittal – The System.

Faster – better – everywhere.

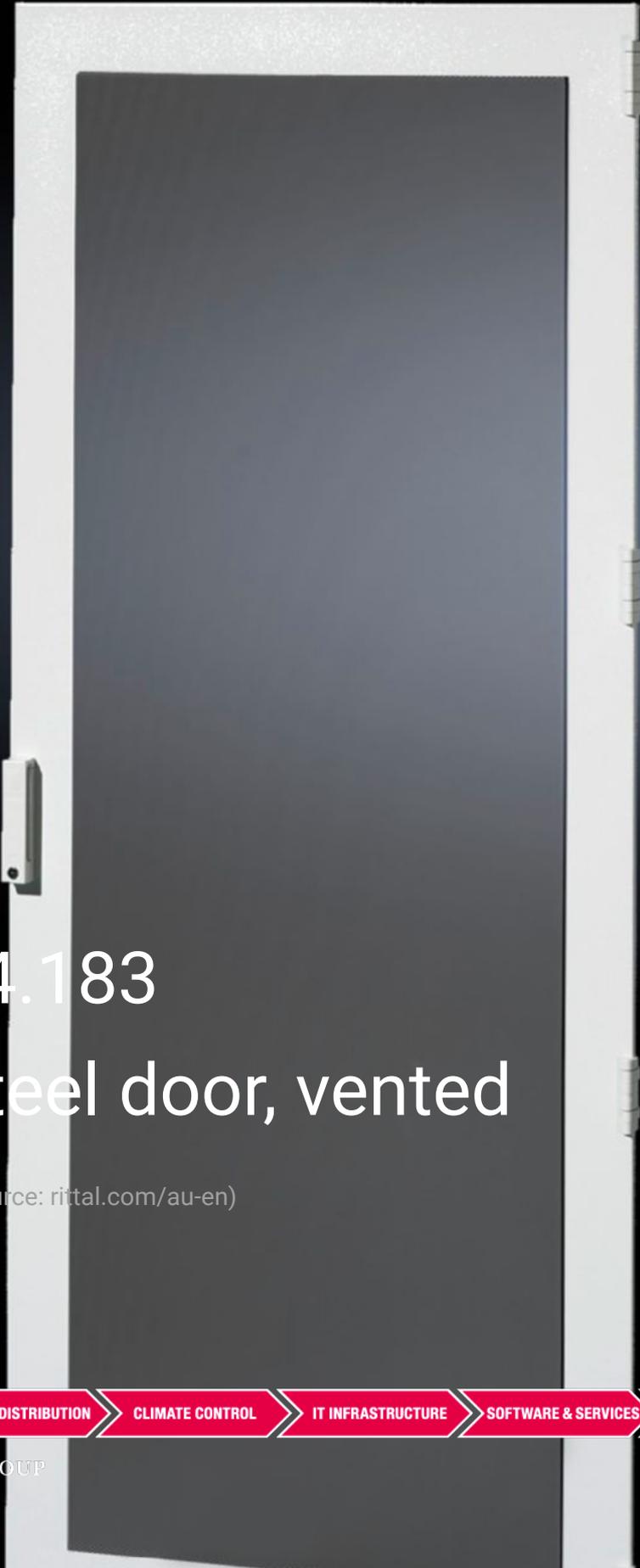

## DK 7824.183

## Sheet steel door, vented

State: 21/12/2025 (Source: [rittal.com/au-en](https://www.rittal.com/au-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7824.183 - Sheet steel door, vented for DK-TS

To replace existing doors. With 180° hinges and swivel handle with security lock no. 3524 E.

## Features

Model No.	DK 7824.183
Product description	With 180° hinges and swivel handle with security lock no. 3524 E, in exchange for comfort handle. For optimum air throughput in network enclosures with a high proportion of active components. Perforated surface with air inlet openings > 78%.
Material	Sheet steel
Colour	RAL 7035
Supply includes	Assembly parts
To fit	Enclosure type: DK-TS Width: 600 mm Height: 1,800 mm
Packs of	1 pc(s).
Net weight	17.005
Gross weight	17.9
Customs tariff number	94039910
EAN	4028177237711
ETIM 9	EC000747
ECLASS 8.0	27182204

# Tender text

TS vented sheet steel door

Extensively perforated door made from 1.5 mm steel sheet, 180° hinges, locking rod with four locking points, swivel handle with 3524 E security lock, ensures optimum ventilation.

A TS 8611.070 comfort handle can also be fitted

The mounting frame integrated inside the door has 25 mm DIN pitch pattern punchings and these enable fan cross members for active maximum configuration ventilation to be fitted as an option.

Material: Sheet steel

Colour: RAL 7035

Dimensions: enclosure (W x H): W: 600 mm H: 1800 mm