


Rittal – The System.

Faster – better – everywhere.

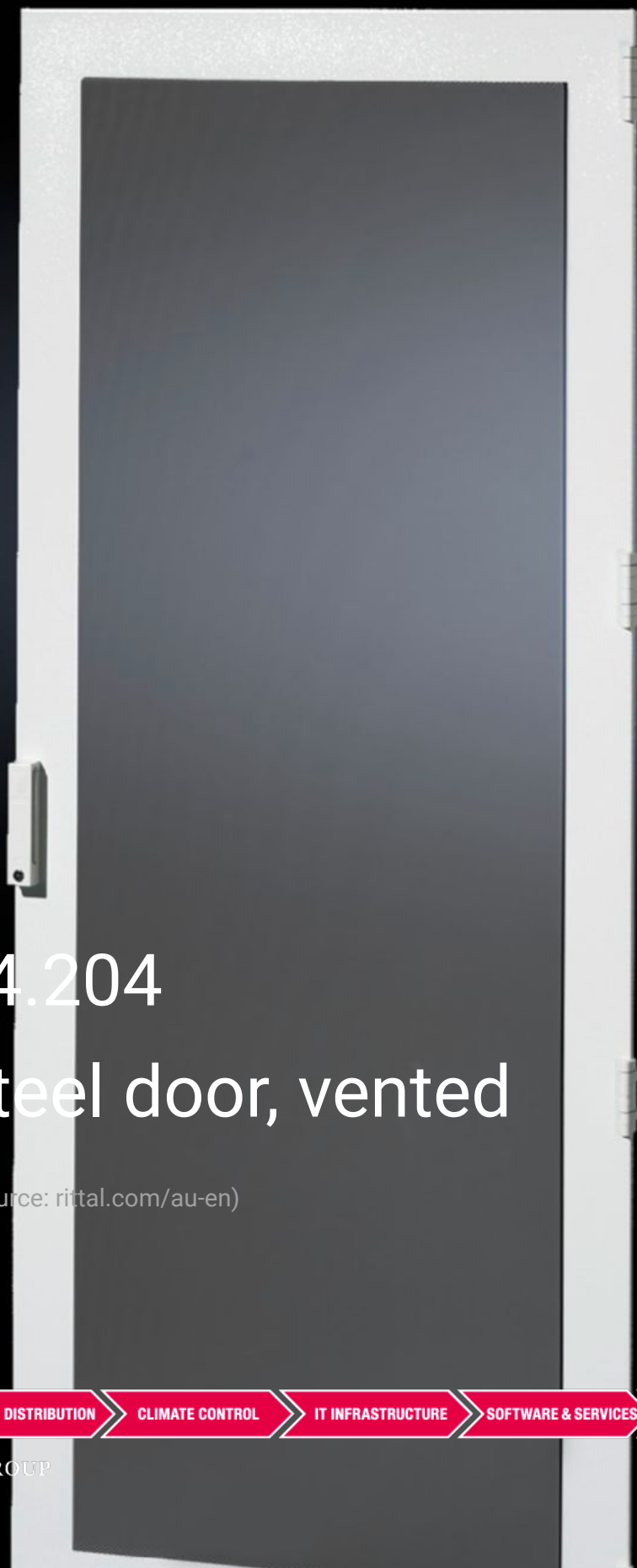

DK 7824.204

Sheet steel door, vented

State: 31/07/2025 (Source: rittal.com/au-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7824.204 - Sheet steel door, vented for DK-TS

To replace existing doors. With 180° hinges and swivel handle with security lock no. 3524 E.

Features

| | |
|-----------------------|---|
| Model No. | DK 7824.204 |
| Product description | With 180° hinges and swivel handle with security lock no. 3524 E, in exchange for comfort handle. For optimum air throughput in network enclosures with a high proportion of active components. Perforated surface with air inlet openings > 78%. |
| Material | Sheet steel |
| Colour | RAL 7035 |
| Supply includes | Assembly parts |
| To fit | Enclosure type: DK-TS Width: 800 mm Height: 2,000 mm |
| Packs of | 1 pc(s). |
| Net weight | 17.4 |
| Gross weight | 18.4 |
| Customs tariff number | 94039910 |
| EAN | 4028177237100 |
| ETIM 9 | EC000747 |
| ECLASS 8.0 | 27182204 |

Tender text

TS vented sheet steel door

Extensively perforated door made from 1.5 mm sheet steel, 180° hinges, locking rod with four locking points, swivel handle with 3524 E security lock, ensures optimum ventilation. A TS 8611.070 comfort handle can be fitted as an option.

The mounting frame integrated inside the door has 25 mm DIN pitch pattern punchings and these enable fan cross members for active maximum configuration ventilation to be fitted as an option.

Material: Sheet steel

Colour: RAL 7035

Dimensions: enclosure (W x H): W: 800 mm H: 2000 mm