


Rittal – The System.

Faster – better – everywhere.

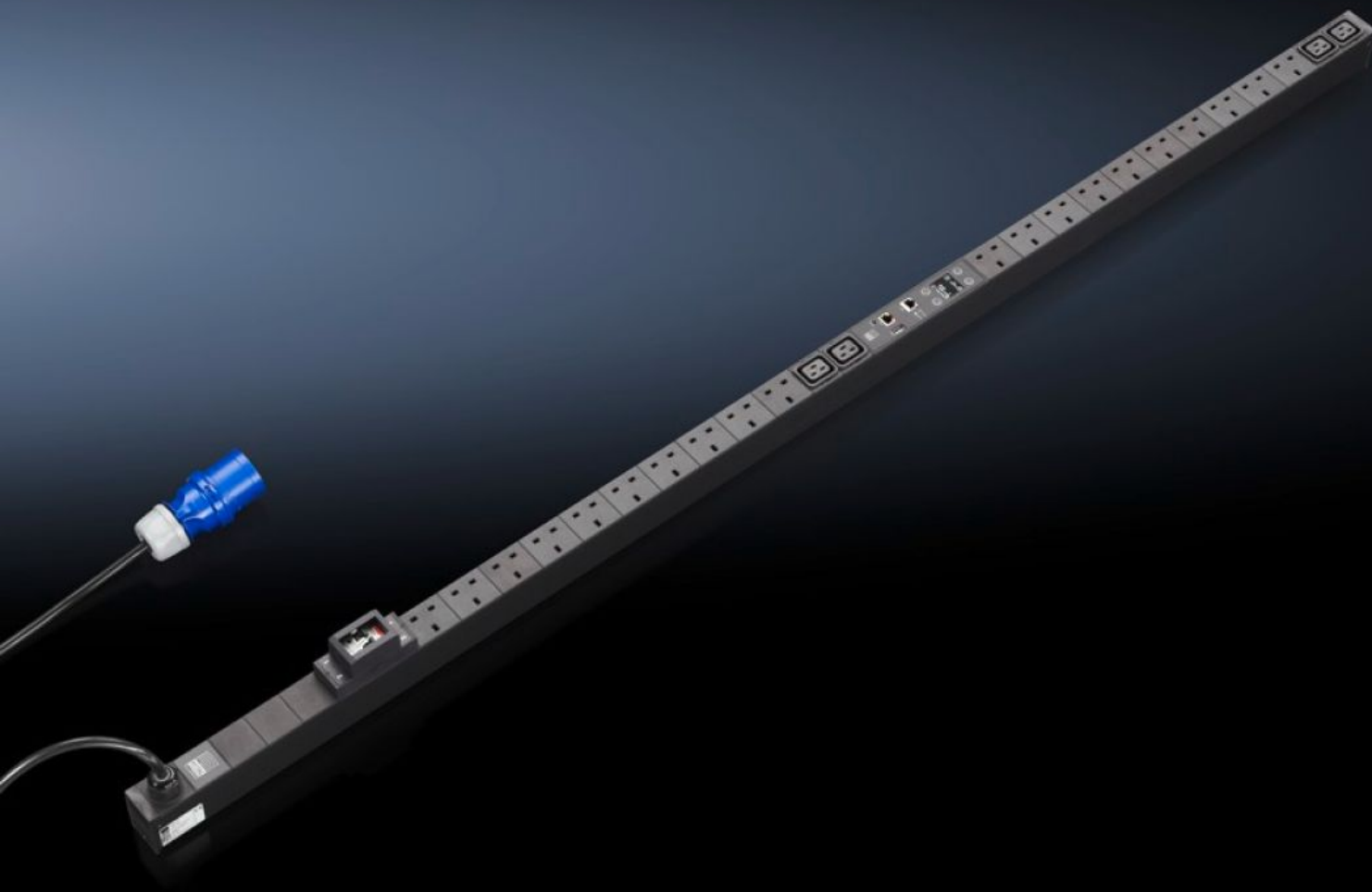

DK 7955.522

PDU UK, metered version

State: 21/05/2024 (Source: [rittal.com/au-en](https://www.rittal.com/au-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7955.522 - PDU UK, metered version

Intelligent PDU with network interface and energy data logging per phase. With networking capability, e.g. IPv4/v6, SNMP, OPC-UA, Modbus/TCP with display. Input with CEE connector (16 A/32 A) with BS 1363 (UK) outputs. Distribution output from 3.7 kW to 22 kW.

Features

Model No.	DK 7955.522
Product description	Energy measurement per phase, i.e. output requirement of an entire IT rack. Thanks to the compact PDU, any IT rack is easily equipped with a professional power distribution system. The TS IT rack even supports tool-free assembly. The compact design allows simple assembly. The OLED display shows the energy consumption. An integral Web server offers a direct network connection with extensive user administration functions. Redundant power is supplied from all phases and additionally via an existing Power over Ethernet network. The PDU offers extensive monitoring functions. Measurement accuracy of 1% guarantees a high level of reliability.
Material	Aluminium section, black anodised
Dimensions	Width: 44 mm Depth: 62 mm Length: 1,955 mm
No. of sockets and type	20 x BS 1363 / 4 x C19
Sockets	20 x GB (type G, BS 1363) 4 x IEC 320 socket C19
Rated current (max.)	32 A
Infeeds	Qty.: 1 Phases per infeed: 1~
Length of connection cable	3 m
Type of electrical connection	CEE
Number RJ45 ports for sensor units max	2
Operating temperature range	0 °C...45 °C

Features

Ambient humidity (non-condensing)	10...95 %
Storage temperature range	-25 °C...70 °C
To fit	Enclosure type: TS IT: ≤ 2,200 mm
Packs of	1 pc(s).
Weight/pack	6.06 kg
Customs tariff number	85366990
EAN	4028177685086
ETIM 7.0	EC000330
ECLASS 8.0	27142604