

# Rittal – The System.

Faster – better – everywhere.



## AX 2474.010 Protective roof

State: 07.04.2026 (Source: [rittal.com/bg-bg](http://rittal.com/bg-bg))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AX 2474.010 - Protective roof for AX

The sloping protective roof reliably protects the enclosure from standing moisture and other soiling from above.

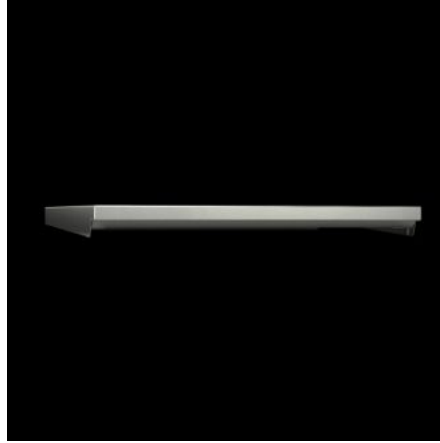

## Features

|                       |  |
|-----------------------|--|
| Model No.             | AX 2474.010  |
| Product description   | The sloping protective roof reliably protects the enclosure from standing moisture and other soiling from above. |
| Material              | Stainless steel 1.4301 (AISI 304)  |
| Surface finish        | Brushed, grain 240   |
| Supply includes       | Assembly parts   |
| Installation options  | May also be screw-fastened for dynamic loads   |
| Dimensions            | Height: 43 mm  |
| Type rating to UL 50E | Type 1<br>Type 3R<br>Type 4<br>Type 4X<br>Type 12  |
| To fit                | Enclosure type: AX<br>Width: = 760 mm<br>Depth: = 300 mm   |
| Packs of              | 1 pc(s).   |
| Net weight            | 3,64 kg  |

# Features

---

|                       |   |
|-----------------------|---|
| Gross weight          | 3,94 kg   |
| Customs tariff number | 94039910  |
| ETIM 9                | EC000744  |
| ETIM 8                | EC000744  |
| ECLASS 8.0            | 27182405  |
| Product description   | AX Protective roof, for WD: 760x300 mm, stainless steel |

---

# Approvals

---

|           |                  |
|-----------|------------------|
| Approvals | UL + C-UL - FTTA |
|-----------|------------------|

---