


# Rittal – The System.

Faster – better – everywhere.

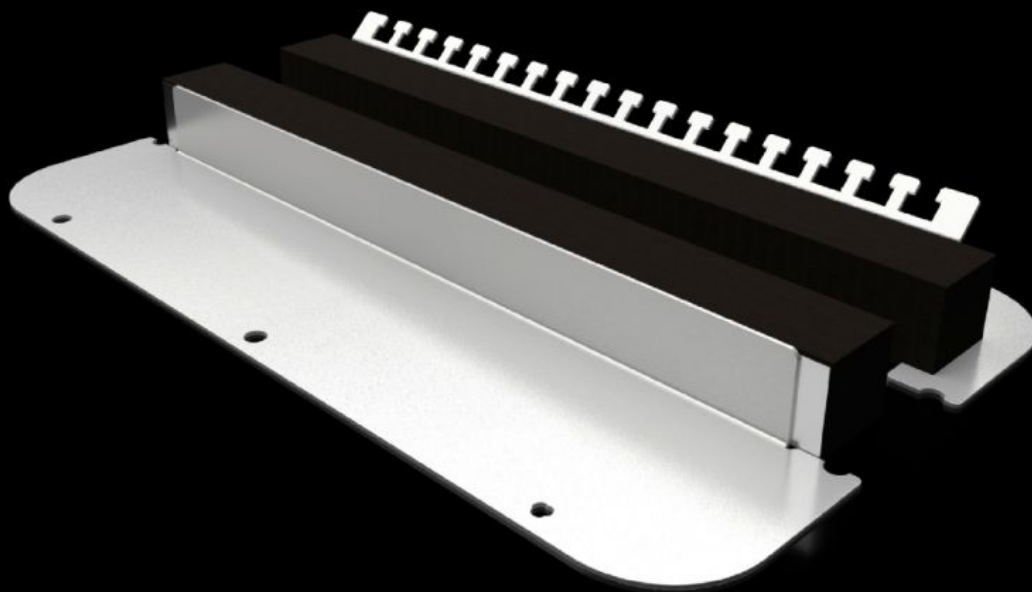

## SZ 2562.450

# Two-part gland plate with foam rubber cable clamp strip

State: 22.05.2026 (Source: [rittal.com/bg-bg](http://rittal.com/bg-bg))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 2562.450 - Two-part gland plate with foam rubber cable clamp strip for AX

The divided gland plate supports simple mounting on the enclosure and offers a range of different installation options. For simple insertion of cables with and without connectors into the enclosure. Special drilled holes in the gland plate ensure automatic potential equalisation during screw-fastening. Bolts, clips and earthing cables are no longer required.

## Features

Model No.	SZ 2562.450
Design	two-piece
Material	Sheet steel
Colour	RAL 7035
Supply includes	Assembly parts
Note	The allocation of gland plate sizes is indicated on the relevant enclosures When installing in enclosure width >760 mm, 2 packs are required
Dimensions	Width: 339 mm Depth: 149 mm
To fit	Enclosure type: AX
To fit Model No.	1031000 1038000 1045000 1077000 1094000 1380000
Gland plate	Size: 2
Packs of	1 pc(s).
Net weight	0,596 kg
Gross weight	0,796 kg
Customs tariff number	73269098

# Features

---

ETIM 8	EC000211
--------	----------

---

ECLASS 8.0	27142421
------------	----------

---

Product description	SZ metal gland plate, two-part, for AX, with foam rubber cable clamp strip, WD: 339x149 mm, for size 2 gland plates
---------------------	---