


Rittal – The System.

Faster – better – everywhere.

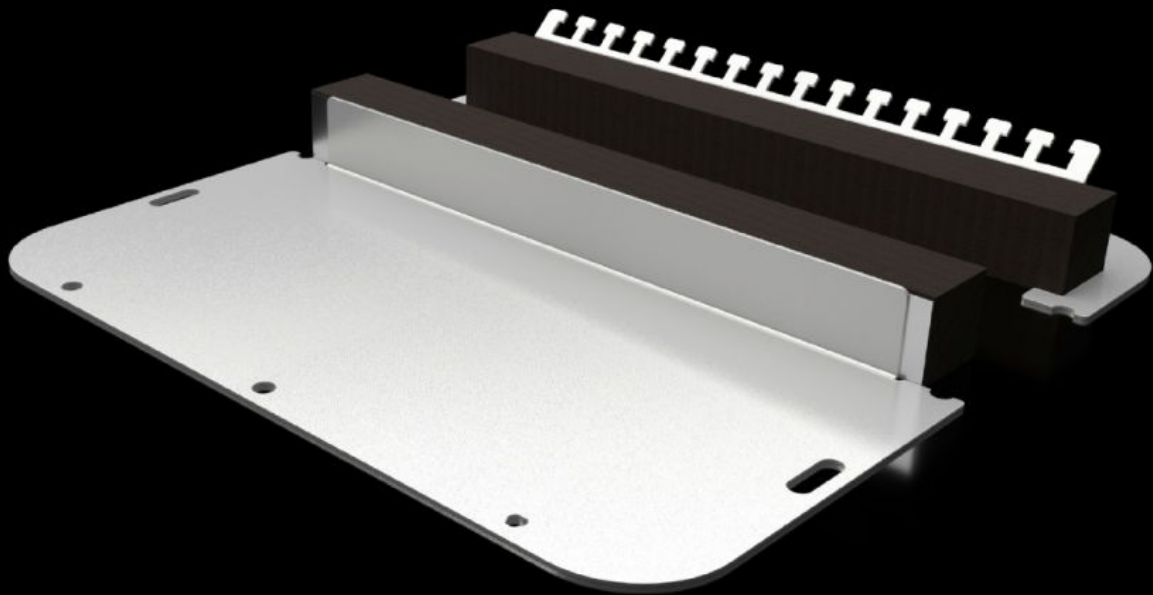

SZ 2565.450

**Two-part gland plate with foam
rubber cable clamp strip**

State: 06.06.2026 (Source: rittal.com/bg-bg)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2565.450 - Two-part gland plate with foam rubber cable clamp strip for AX

The divided gland plate supports simple mounting on the enclosure and offers a range of different installation options. For simple insertion of cables with and without connectors into the enclosure. Special drilled holes in the gland plate ensure automatic potential equalisation during screw-fastening. Bolts, clips and earthing cables are no longer required.

Features

Model No.	SZ 2565.450
Design	two-piece
Material	Sheet steel
Colour	RAL 7035
Supply includes	Assembly parts
Note	The allocation of gland plate sizes is indicated on the relevant enclosures When installing in enclosure width >760 mm, 2 packs are required
Dimensions	Width: 301 mm Depth: 221 mm
To fit	Enclosure type: AX
To fit Model No.	1037.000 1055.000 1073.000 1180.000 1280.000 1338.000 1181.000 1281.000
Gland plate	Size: 5
Packs of	1 pc(s).
Net weight	0,95 kg
Gross weight	1,02 kg

Features

PCF per pack (cradle-to-gate)	3.9 kg CO2 eq (Cat B)
Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
Customs tariff number	73079100
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421
Product description	SZ Metal gland plate, two-part, for AX, with foam rubber cable clamp strip, WD 301x221 mm, for gland plate size 5