


**Rittal – The System.**

Faster – better – everywhere.

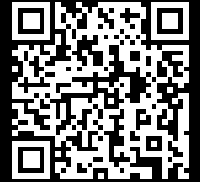

**AX 2820.082**

**Base/plinth corner piece with base/  
plinth trim panels, front and rear,  
200 mm**

State: 20.06.2024 (Source: [rittal.com/bg-bg](http://rittal.com/bg-bg))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AX 2820.082 - Base/plinth corner piece with base/plinth trim panels, front and rear, 200 mm for AX

Base/plinth corner piece with large opening for optimum access to the screw-fastening point, may be concealed with a plastic corner cover.

## Features

Model No.	AX 2820.082
Product description	Base/plinth corner piece with large opening for optimum access to the screw-fastening point, may be concealed with a plastic corner cover.
Material	Base/plinth corner piece: Sheet steel Base/plinth trim panel front/rear: Sheet steel Corner cover: Plastic
Colour	RAL 9005
Supply includes	4 base/plinth corner pieces, 200 mm high 4 corner covers 1 base/plinth trim panel, front/rear, 200 mm high 2 base/plinth trim panels, front/rear, 100 mm high Assembly parts
Note	Base/plinth elements are required at the side to finish off a base/plinth unit
Dimensions	Height: 200 mm
To fit	Enclosure type: AX Width: = 800 mm
Type rating to UL 50E	Type 1, 3R, 4, 12
Packs of	2 pc(s).
Weight/pack	3,85 kg
Customs tariff number	94039910
EAN	4028177942639
ETIM 8	EC000721

# Features

---

ETIM 7.0	EC000721
----------	----------

---

ECLASS 8.0	27182003
------------	----------

# Approvals

---

Approvals	UL + C-UL - FTTA
-----------	------------------