


# Rittal – The System.

Faster – better – everywhere.

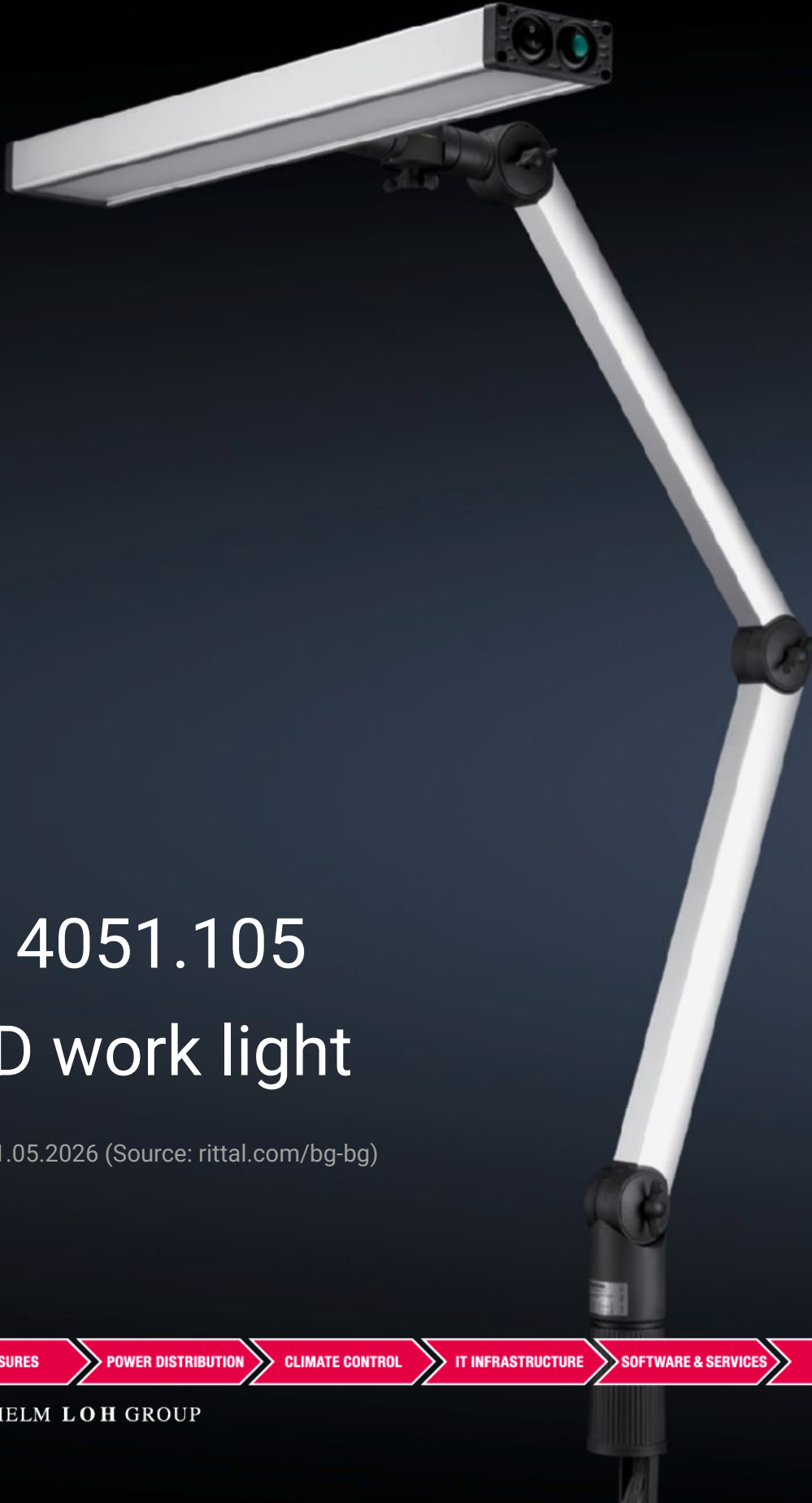

## AS 4051.105 LED work light

State: 11.05.2026 (Source: [rittal.com/bg-bg](http://rittal.com/bg-bg))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4051.105 - LED work light for WS 540

For attaching to the table top, with clamping device.



## Features

|                            |   |
|----------------------------|---|
| Model No.                  | AS 4051.105   |
| Product description        | For attaching to the table top, with clamping device.   |
| Benefits                   | <p>Bright, glare- and flicker-free lighting, homogeneous and shadow-free</p> <p>Selectable colour temperature between warm white, neutral white and daylight white promotes concentration and reduces symptoms of fatigue</p> <p>Excellent colour fidelity and high contrast</p> <p>Aluminium spring arm with 3D head joint, swivelling and lockable for free positioning of the light source</p> |
| Technical specifications   | <p>Spring arm: Length 970 mm</p> <p>Colour reproduction: 94 – 98 Ra</p> <p>Transmission angle: 100°</p>   |
| Material                   | <p>Light housing: Aluminium</p> <p>Glare control: Macrolon</p>  |
| Supply includes            | <p>LED work light</p> <p>Assembly parts</p>   |
| Power consumption          | 26 W  |
| Length of connection cable | 3 m   |
| Connection options         | Plug-in power supply (CEE 7/16) with AC adaptor   |
| Light                      | 84 SMD LEDs   |

# Features

|                             |  |
|-----------------------------|--|
| Protection class            | III (SELV)                                       |
| Luminous flux               | 2930 lm  |
| To fit Model No.            | 4051.100   |
| Operating temperature range | -10 °C...40 °C                                   |
| Rated operating voltage     | 110 V - 240 V, 1~, 50 Hz/60 Hz                   |
| Dimensions                  | Width: 545 mm<br>Height: 90 mm<br>Depth: 35 mm   |
| Packs of                    | 1 pc(s).   |
| Net weight                  | 2,5 kg   |
| Gross weight                | 4,2 kg   |
| Customs tariff number       | 94054990   |
| ETIM 9                      | EC002778   |
| ETIM 8                      | EC002778   |
| ECLASS 8.0                  | 36629090   |
| Product description         | LED work light for WS 540, dimmable, 230 V/50 Hz |