


**Faster – better – everywhere.**

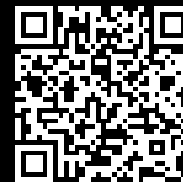

# SZ 4315.710

## Door-operated switch

State: 16.07.2025 (Source: [rittal.com/bg-bg](http://rittal.com/bg-bg))



**ENCLOSURES**

## ► POWER DISTRIBUTION

## CLIMATE CONTROL

## IT INFRASTRUCTURE

## ► SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

# SZ 4315.710 - Door-operated switch

with mounting accessories, with or without connection cable.

## Features

Model No.	SZ 4315.710
Design	With connection cable
Length	600 mm
Rated impulse withstand voltage, phase to phase	6000 V AC
Rated insulation voltage	400 V AC
Installation options	for compact light
Dimensions	Length: 600 mm
Electrical connection	240 V AC/2.5 A 125 V AC/2.5 A 24 V AC/2.5 A 24 V DC/2.5 A
Rated operating voltage	400 V
IP protection category to IEC 60 529	IP 40
Packs of	1 pc(s).
Net weight	0.11
Gross weight	0.139
Customs tariff number	85365019
EAN	4028177581371
E-Number Sweden	E3404495
ETIM 9	EC002626
ETIM 8	EC002626
ECLASS 8.0	27189266

# Approvals

---

Approvals

CQC  
CQC-CCC

---

Explanations

Declaration of conformity  
Declaration of conformity UK