

Rittal – The System.

Faster – better – everywhere.



DK 7030.070 CMC III mounting units

State: 05.03.2026 (Source: [rittal.com/bg-bg](https://www.rittal.com/bg-bg))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7030.070 - CMC III mounting units

To accommodate CMC III components.

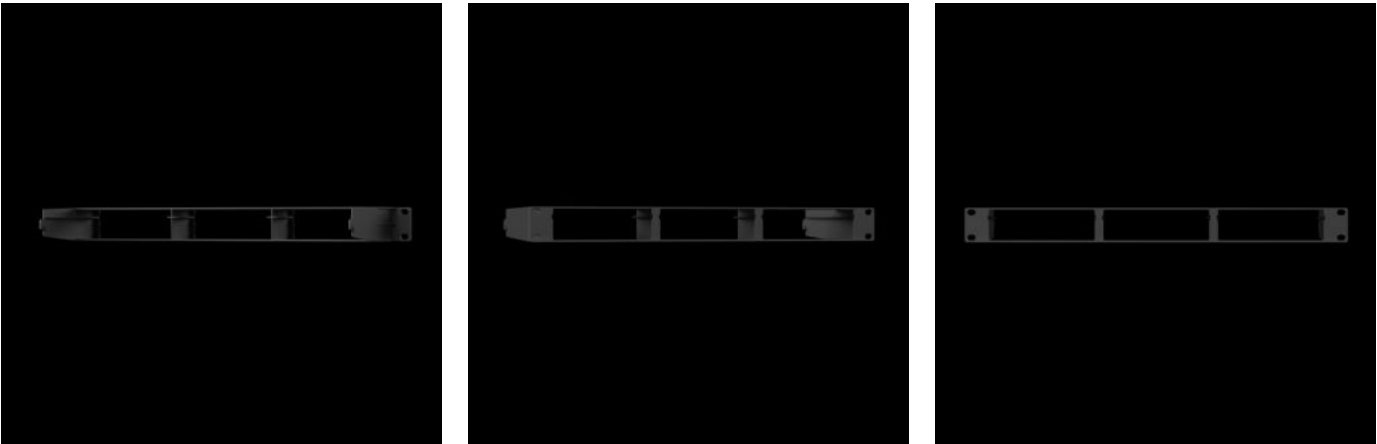

Features

Model No.	DK 7030.070
Design	For PU, PU Compact, control units, CMC III CAN bus unit and CMC III power pack.
Product description	Depending on the design, the mounting unit can accommodate 1 or 3 Processing Units / sensor units etc. The 482.6 mm version (19" levels) can accommodate 3 units. The enclosure frame version can accommodate 1 unit.
Benefits	Fire protection: Self-extinguishing to UL 94 HB
Applications	Accommodation of CMC III components.
Function principle	CMC III Processing Unit CMC III Processing Unit Compact CMC III control unit CMC III power pack CMC III LTE unit CMC III door control module
Material	Sheet steel
Surface finish	Zinc plated, passivated
Supply includes	Blanking cover
Number of locations	3

Features

Installation options	482.6 mm (19") level
Dimensions	Width: 482.6 mm Depth: 141 mm
Packs of	1 pc(s).
Net weight	0,8 kg
Gross weight	1,02 kg
Customs tariff number	73269098
ETIM 9	EC002627
ECLASS 8.0	27189253
Product description	DK CMC III mounting units, Accommodation of CMC III components, For 482.6 mm (19"), WHD: 138x40x132 mm

Tender text

7030.070

CMC III mounting unit, 1 U

Packs of 1

Used to mount PU, PU Compact, control units, CMC III CAN bus unit and CMC III power pack.

The mounting unit can accommodate up to three units and is attached in the 19" frame. The components to be mounted are plugged in at the front and automatically lock into place. In the rear section of the system there is an integrated option for fastening the CMC III cable clamp straps 7030.087.

Technical specifications:

Width: 482.6 mm (19")

Height: 44.25 mm (1 U)

Depth: 141 mm

Material: Zinc-plated sheet steel

Temperature application range:

0 °C to 55 °C

Humidity range:

5% to 95% relative humidity, non-condensing

Included in the pack: Mounting unit and assembly parts