


Rittal – The System.

Faster – better – everywhere.

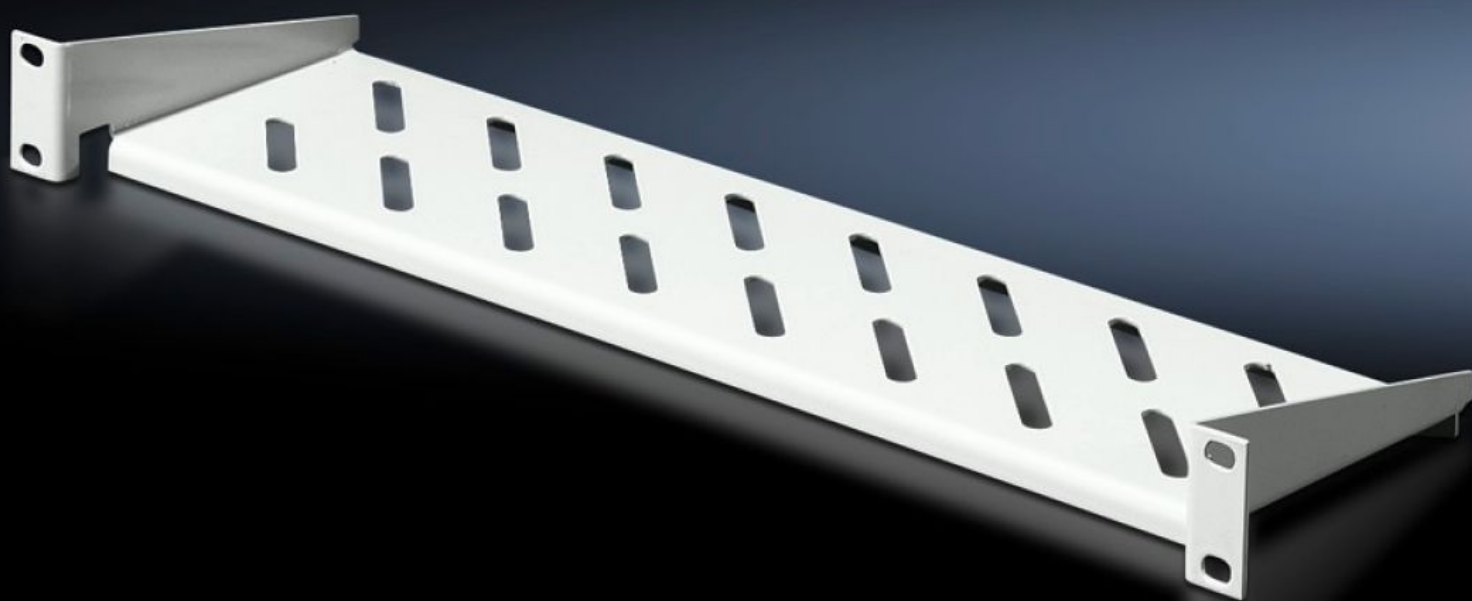

DK 7119.140

**Component shelf 1 U, static
installation**

State: 23.08.2025 (Source: [rittal.com/bg-bg](https://www.rittal.com/bg-bg))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES


FRIEDHELM LOH GROUP



DK 7119.140 - Component shelf 1 U, static installation

482.6 mm (19") system punchings

482.6 mm (19")/535 mm (metric), support surface for small active components such as modems or mini-hubs in 482.6 mm (19") or metric levels, load capacity: 10 kg.

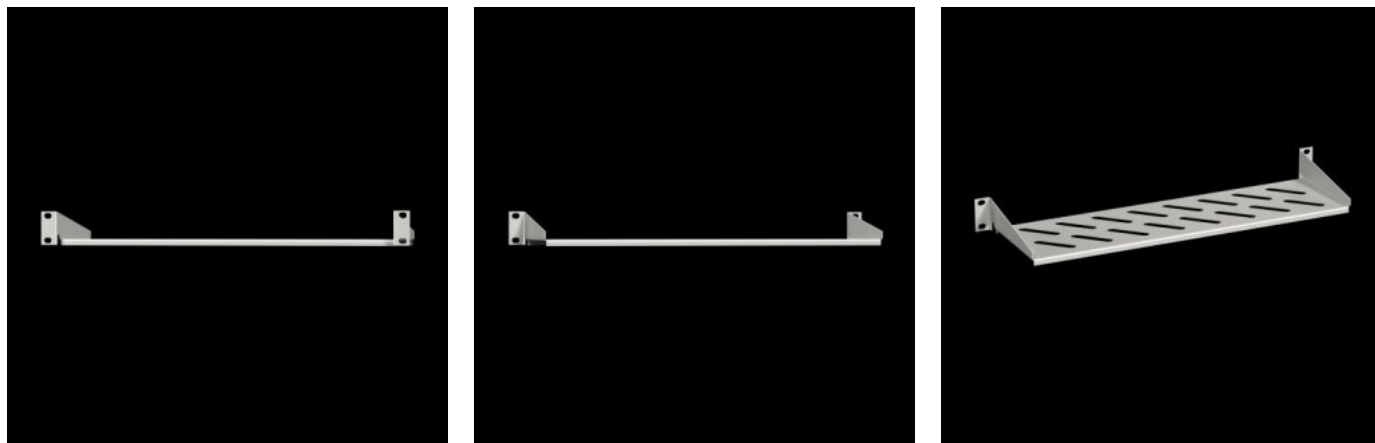

Features

Model No.	DK 7119.140
Design	482.6 mm (19") version
Product description	The ideal support surface for small active components such as modems or mini-hubs.
Material	Sheet steel
Colour	RAL 7035
Load capacity	10 kg surface load, static
Note	Not suitable for combination with telescopic slides. Free installation height inside the U approx. 35 mm
Dimensions	Width: 482.6 mm Depth: 140 mm
Packs of	1 pc(s).
Net weight	0.781
Gross weight	0.881
PCF per pack (cradle-to-gate)	3.2 kg CO2 eq (Cat B)

Features

Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
Customs tariff number	94039910
EAN	4028177221444
ETIM 9	EC002620
ECLASS 8.0	27189261

Tender text

482.6 mm (19 inch) single-level component shelf,
D: 140 mm

Load capacity: 10 kg surface load, static
Material: Sheet steel, spray finished in RAL 7035