


**Rittal – The System.**

Faster – better – everywhere.

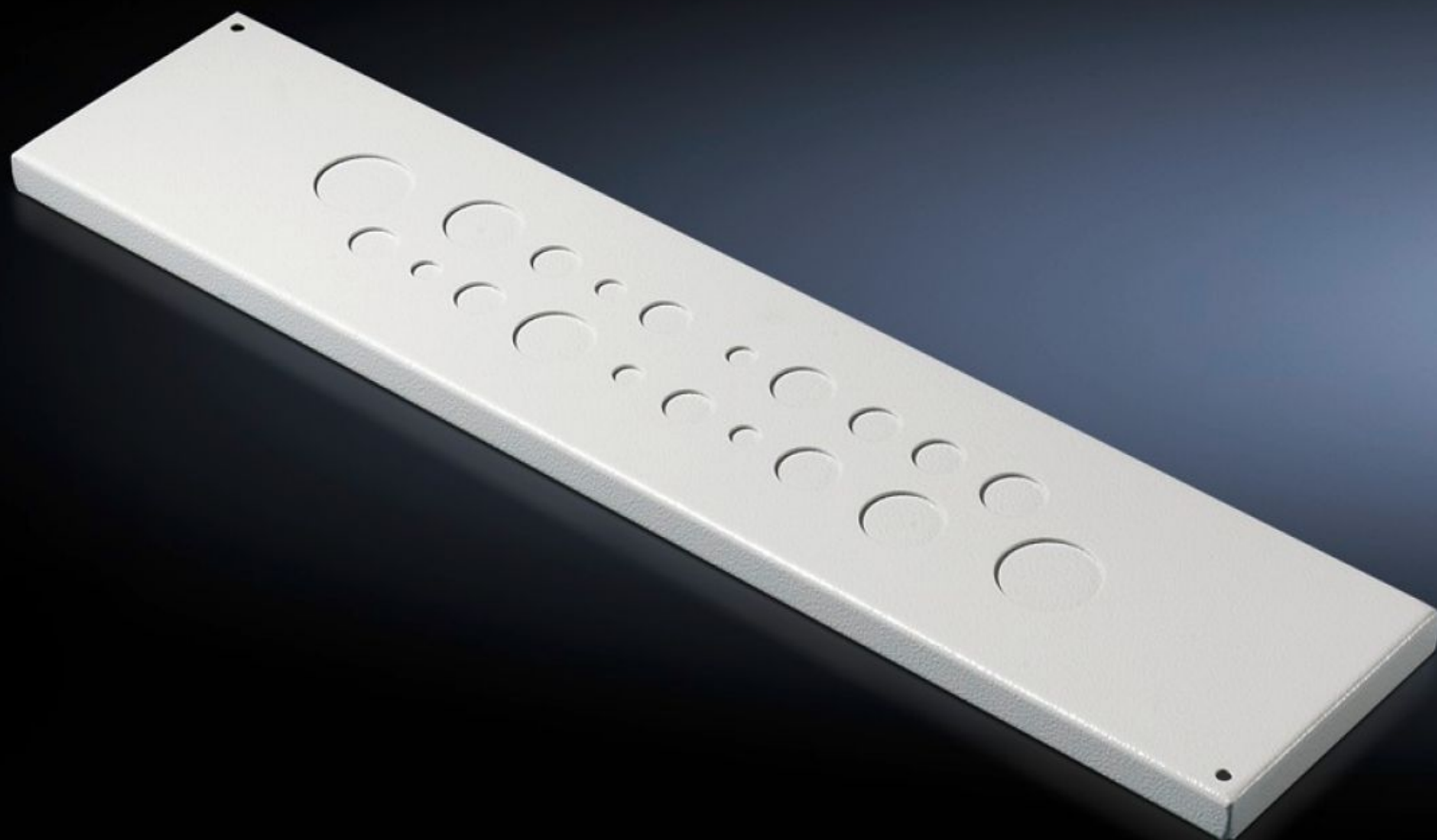

**EL 7705.235**

**Gland plate for metric cable glands**

State: 11.07.2025 (Source: [rittal.com/bg-bg](https://www.rittal.com/bg-bg))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# EL 7705.235 - Gland plate for metric cable glands for EL

Folded gland plate with foamed-in seal and pre-punched, knock-out holes for metric cable glands.

## Features

Model No.	EL 7705.235
Product description	Folded gland plate with foamed-in seal and pre-punched, knock-out holes for metric cable glands M12, M20, M25, M32, M40.
Material	Sheet steel, 1.5 mm
Colour	RAL 7035
No. of metric knockouts	4 x M12 8 x M20 6 x M25 1 x M32 1 x M40
Dimensions	Width: 599 mm Depth: 133.5 mm
Protection category to IEC 60 529	IP 55
Number knockouts	4 8 6 1 1
Metric diameter	M12 M20 M25 M32 M40
Packs of	1 pc(s).
Net weight	1.55
Gross weight	1.64
PCF per pack (cradle-to-gate)	6.2 kg CO2 eq (Cat B)

# Features

Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
Customs tariff number	73269098
EAN	4028177389854
ETIM 9	EC000211
ECLASS 8.0	27142421