
 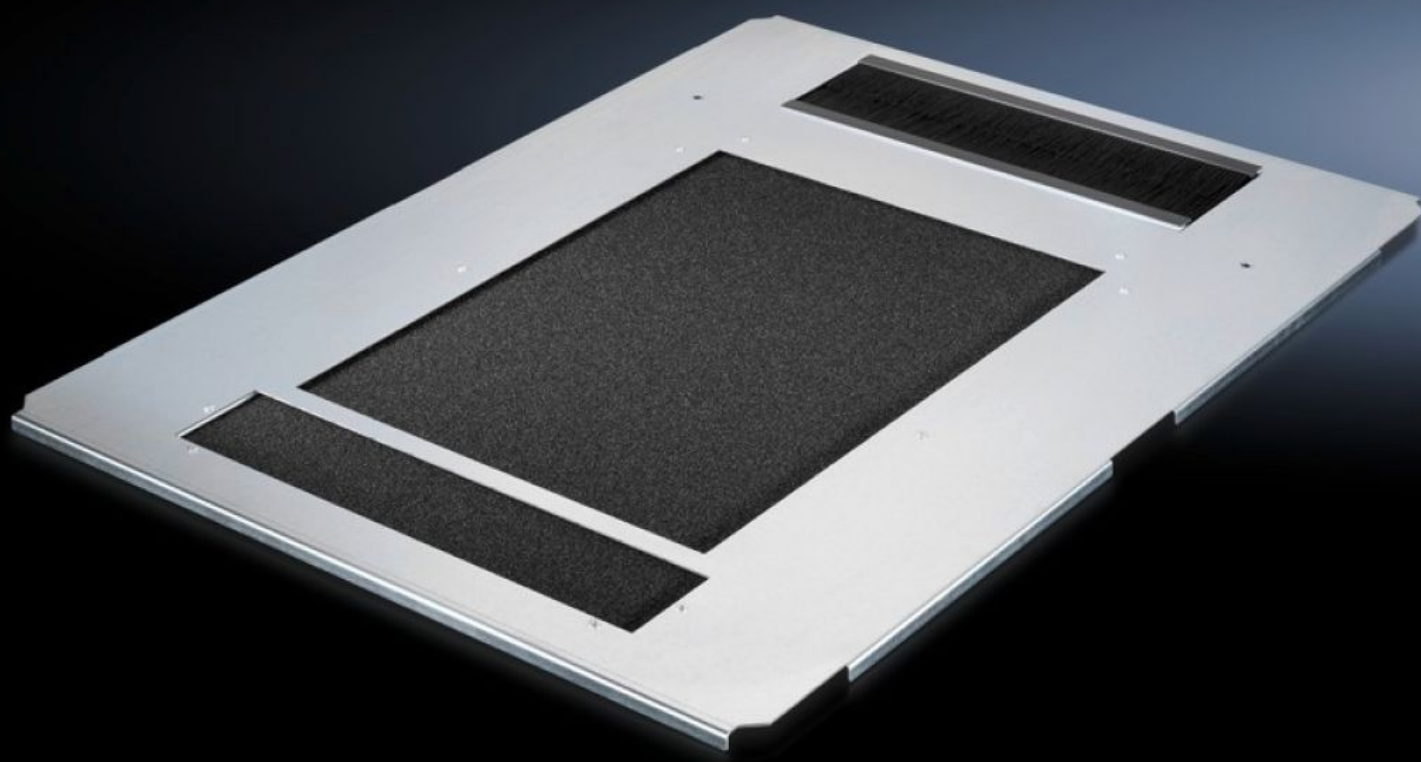


# Rittal – The System.

Faster – better – everywhere.



## DK 7825.812

## Gland plate, one-piece, vented

State: 18.07.2025 (Source: [rittal.com/bg-bg](https://www.rittal.com/bg-bg))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7825.812 - Gland plate, one-piece, vented for DK-TS

Gland plate, one-piece, vented, for TS, with ventilation holes, cut-out for cable entry at the rear, with brush strip.

## Features

Model No.	DK 7825.812
Product description	Punched for ventilation with a cut-out in the rear for cable entry, which is concealed with brush strip.
Material	Sheet steel
Surface finish	Zinc-plated
Supply includes	Assembly parts
To fit	Enclosure type: TS 8 Width: 800 mm Depth: 1,200 mm
Packs of	1 pc(s).
Net weight	8.265
Gross weight	8.7
Customs tariff number	73269098
EAN	4028177547957
ECLASS 8.0	27189261

# Tender text

Gland plate, vented, with brush strip for cable entry for TS.

The extensive perforation of the gland plate enables air to be supplied to the components from below. The base plate has an opening to the rear for cable entry into the enclosure. The opening has a brush strip and runs open to the outside. This means that the plate can be taken out for more straightforward fitting during installation work at any time, even for already existing pre-installation.

Material: Sheet steel, zinc-plated, passivated  
Dimensions (W x H): 800 mm x 1,200 mm