


# Rittal – The System.

Faster – better – everywhere.

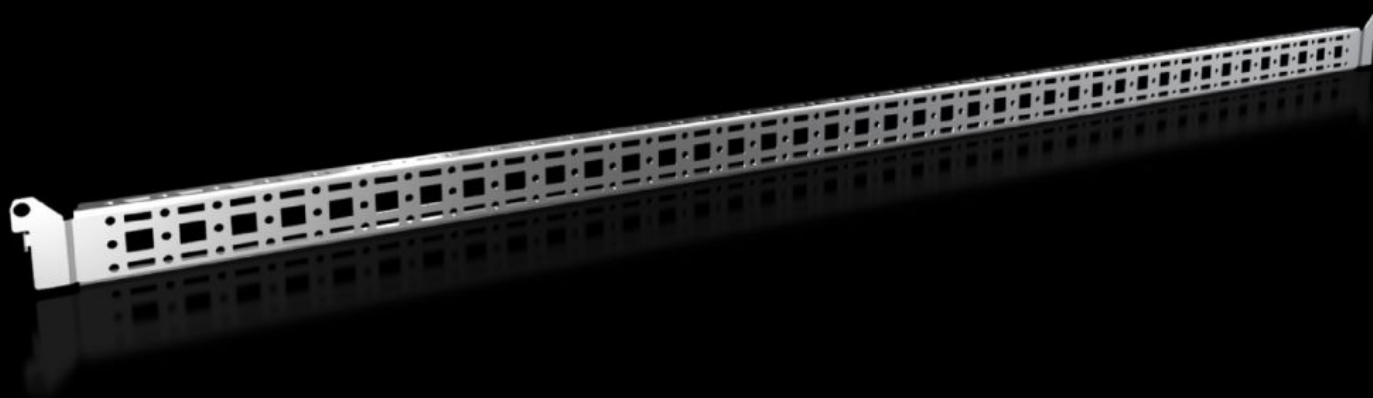

## VX 8619.770

## Punched section with mounting flange, 14 x 39 mm

State: 09.07.2025 (Source: [rittal.com/bg-bg](https://www.rittal.com/bg-bg))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# VX 8619.770 - Punched section with mounting flange, 14 x 39 mm for VX, VX SE, PC, IW, AX

For securing cable ducts, cable conduit holders, equipment installed on the door, etc.



## Features

|   |   |
|---|---|
| Model No.                               | VX 8619.770   |
| Product description                     | For attaching cable ducts, cable conduit holders, equipment installed on the door, etc.   |
| Material                                | Sheet steel   |
| Surface finish                          | Zinc-plated   |
| Supply includes                         | Assembly parts  |
| Distance between fixing points          | 1075 mm   |
| AX installation options                 | In enclosure height 1200 mm, in conjunction with rail for interior installation AX  |
| AX stainless steel installation options | In enclosure height 1200 mm   |
| Assembly instruction                    | For installation in AX sheet steel, only in conjunction with rail for interior installation AX                                      |
| Note                                    | For installing your own components on the punched section with mounting flange, metal screws or self-tapping M5 screws are required |

# Features

|                       |   |
|-----------------------|---|
| To fit                | Enclosure type: AX<br>Suitable for width or height or depth: 1,200 mm |
| Packs of              | 4 pc(s).  |
| Net weight            | 2.16  |
| Gross weight          | 2.28  |
| Customs tariff number | 73269098  |
| EAN                   | 4028177926837   |
| E-Number Sweden       | E3465285  |
| ETIM 9                | EC002620  |
| ECLASS 8.0            | 27189234  |