


Rittal – The System.

Faster – better – everywhere.

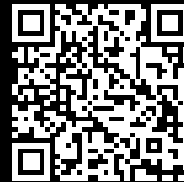

TS 8801.500 Partial doors

State: 22.12.2025 (Source: [rittal.com/bg-bg](https://www.rittal.com/bg-bg))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



TS 8801.500 - Partial doors for TS

Door may be optionally hinged on the right or left.



Features

Model No.	TS 8801.500
Product description	Suitable for TS enclosures instead of a door or rear panel. The partial doors may be combined with one another as required. A trim panel is required at the top and bottom in each case. Door may be optionally hinged on the right or left. In the case of doors without viewing panel (height 600 – 1000 mm), monitor frame SZ 2305.000 may be installed. Standard double-bit lock insert may be exchanged for lock inserts, type F, and from 600 mm height, for comfort handle.
Material	Sheet steel, 2 mm
Colour	RAL 7035
Supply includes	Cross member Hinges Lock components Assembly parts
Dimensions	Width: 600 mm Height: 1,000 mm

Features

IP protection category to IEC 60529	IP 54 for a completed enclosure
Packs of	1 pc(s).
Net weight	11.983
Gross weight	12.614
Customs tariff number	94039910
EAN	4028177250604
ETIM 9	EC000747
ECLASS 8.0	27182204