


Rittal – The System.

Faster – better – everywhere.

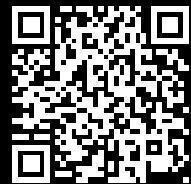

KL 1527.010

KL Terminal Boxes

State: 2026-02-24 (Source: [ittal.com/ca-en](https://www.ittal.com/ca-en))



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

KL 1527.010 - KL Terminal Boxes Stainless steel

Terminal box of stainless steel 1.4301, (AISI 304). Protection category IP 66.

Features

Model No.	KL 1527.010
Material	Housing: Stainless steel 1.4301 (AISI 304) Cover: Stainless steel 1.4301 (AISI 304), all-round foamed-in PU seal
Surface finish	Housing and cover: Brushed, grain 180
Supply includes	Housing with cover Quick-release fasteners including plastic bushings
Protection category NEMA	NEMA 4X
Protection category IP to EN 60 529	IP 66
IK code	IK08
Dimensions	Width: 150 mm Height: 150 mm Depth: 120 mm
Material thickness - cover	1.25 mm
Material thickness - enclosure	1.25 mm
Lock	No. of locks: 4
Base material	Stainless steel 1.4301 (AISI 304)
Packaging unit	1 pc(s).
Net weight	1.4 kg
Gross weight	1.484 kg
Customs tariff number	84879090
ETIM 9	EC000261
ETIM 8	EC000261
ECLASS 8.0	27180101

Features

Product description

KL Terminal box, WHD: 150x150x120 mm, Stainless steel 1.4301, without mounting plate, with cover, without gland plate

Approvals

Approvals

Bureau Veritas
DNV-GL
UL + C-UL (listed)

Explanations

Declaration of conformity
Declaration of conformity UK