


Rittal – The System.

Faster – better – everywhere.

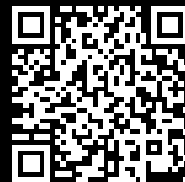

KL 1527.010

KL Terminal Boxes

State: 2025-12-14 (Source: [rittal.com/ca-en](https://www.rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



KL 1527.010 - KL Terminal Boxes Stainless steel

Terminal box of stainless steel 1.4301, (AISI 304). Protection category IP 66.

Features

Model No.	KL 1527.010
Material	Housing: Stainless steel 1.4301 (AISI 304) Cover: Stainless steel 1.4301 (AISI 304), all-round foamed-in PU seal
Surface finish	Housing and cover: Brushed, grain 180
Supply includes	Housing with cover Quick-release fasteners including plastic bushings
Protection category NEMA	NEMA 4X
Protection category IP to EN 60529	IP 66
IK code	IK08
Dimensions	Width: 150 mm Height: 150 mm Depth: 120 mm
Material thickness - cover	1.25 mm
Material thickness - enclosure	1.25 mm
Lock	No. of locks: 4
Base material	Stainless steel 1.4301 (AISI 304)
Packaging unit	1 pc(s).
Net weight	1.4
Gross weight	1.484
Customs tariff number	84879090
EAN	4028177663329
E-Number Sweden	E3404378
ETIM 9	EC000261

Features

ETIM 8	EC000261
ECLASS 8.0	27180101

Approvals

Approvals	Bureau Veritas DNV-GL UL + C-UL (listed)
Explanations	Declaration of conformity Declaration of conformity UK