


Rittal – The System.

Faster – better – everywhere.

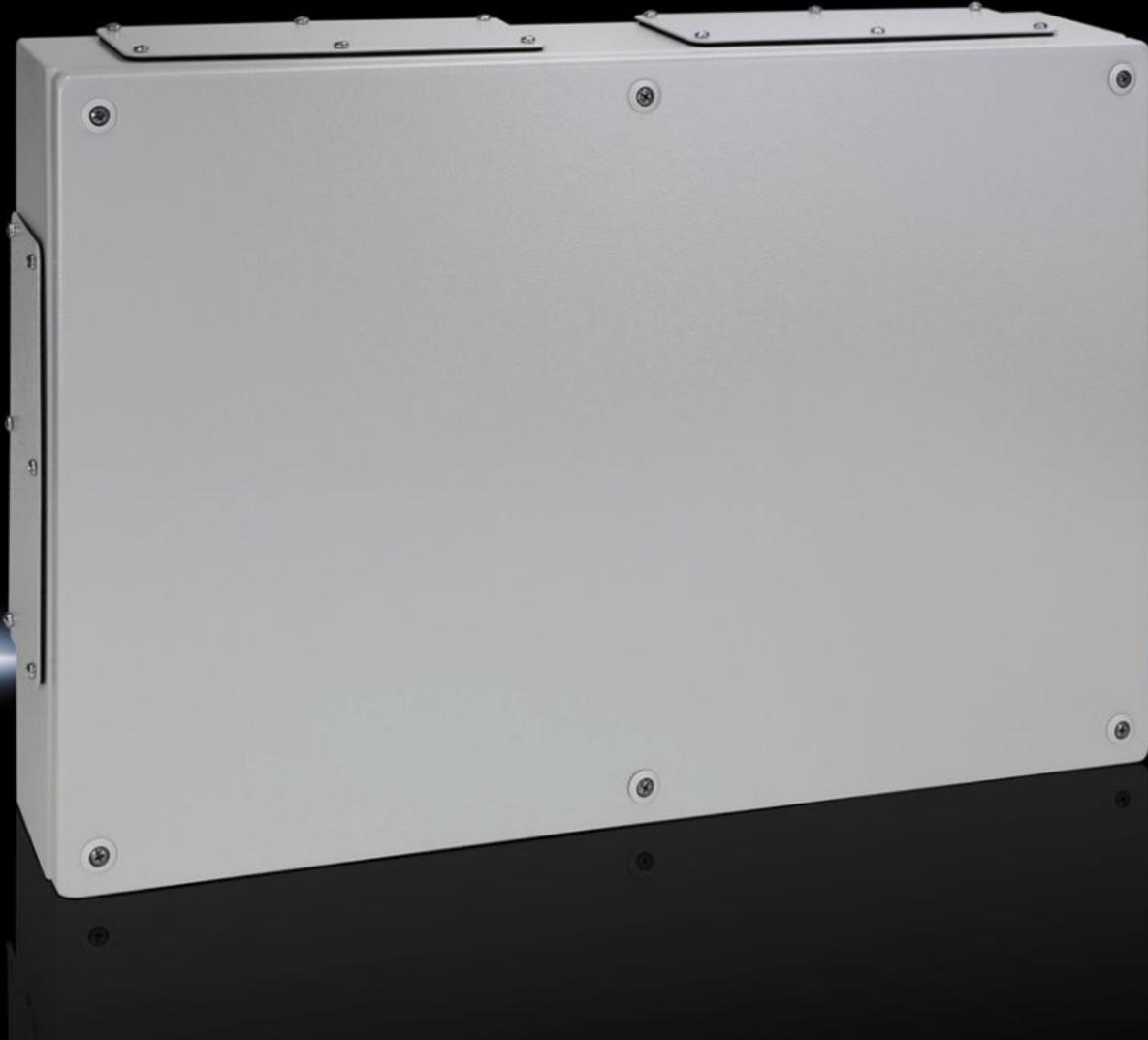

KL 1540.510 KL Terminal Boxes

State: 2026-05-09 (Source: rittal.com/ca-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



KL 1540.510 - KL Terminal Boxes with gland plate

Spray-finished housing with sheet steel cover, with gland panel. Protection category IP 55.



Features

| | |
|------------------------------------|---|
| Model No. | KL 1540.510 |
| Material | Housing: Carbon steel Cover: Carbon steel, all-round foamed-in PU seal |
| Surface finish | Housing and cover: Dipcoat primed, powder-coated on the outside, textured paint |
| Color | RAL 7035 |
| Supply includes | Housing with cover Quick-release fasteners including plastic bushings Carbon steel flange plates with seals and assembly components |
| Protection category NEMA | NEMA 12 |
| Protection category IP to EN 60529 | IP 55 |
| IK code | IK08 |
| Dimensions | Width: 600 mm Height: 400 mm Depth: 120 mm |
| Material thickness - cover | 1.25 mm |
| Material thickness - enclosure | 1.38 mm |

Features

| | |
|-----------------------|--|
| Flange Plates | : 1 + 1 Size of gland plate for bus enclosures, position left/right: 2 : 2 + 2 Size of gland plate for bus enclosures, position top/bottom: 2 |
| Base material | Carbon steel |
| Packaging unit | 1 pc(s). |
| Net weight | 8.66 kg |
| Gross weight | 9.316 kg |
| Customs tariff number | 73269098 |
| ECLASS 8.0 | 27180101 |
| Product description | KL Terminal box, WHD: 600x400x120 mm, Sheet steel, without mounting plate, with cover, with gland plate |

Approvals

| | |
|--------------|--|
| Approvals | Bureau Veritas DNV Lloyds Register UL + C-UL (listed) |
| Explanations | Declaration of conformity UK |
