

# Rittal – The System.

Faster – better – everywhere.



## DK 2094.400 Slot-in cable gland, 482.6 mm (19")

State: 2025-05-25 (Source: [rittal.com/ca-en](https://rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 2094.400 - Slot-in cable gland, 482.6 mm (19")

Consist of an expanding nut which is inserted into the square hole at the front and then secured with the fastening screw.

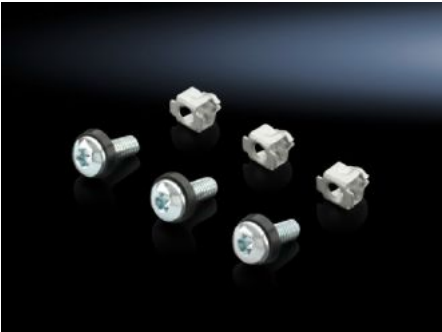

## Features

Model No.	DK 2094.400
Version	Size of mounting hole 9.5 x 9.5 mm
Product description	The screw fastening consists of an expanding nut which is inserted into the square hole at the front only and then secured with the fastening screw. When the screw is tightened the captive nut expands in this way securing the elements. Holder tightening zone 1.2 – 4.5 mm. Multi-tooth screw head, bit size T 30.
Material	Carbon steel
Surface finish	Zinc-plated
Supply includes	Flat-head screw Expanding nuts Plastic washers
Dimensions	Thread: M6 Thread length: 16 mm
Packaging unit	50 pc(s).

# Features

Net weight	0.3
Gross weight	0.38
PCF per pack (cradle-to-gate)	1.3 kg CO2 eq (Cat B)
Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
Customs tariff number	73181900
EAN	4028177488847
E-Number Sweden	E7239814
ETIM 9	EC002358
ETIM 8	EC002358
ECLASS 8.0	23110815