
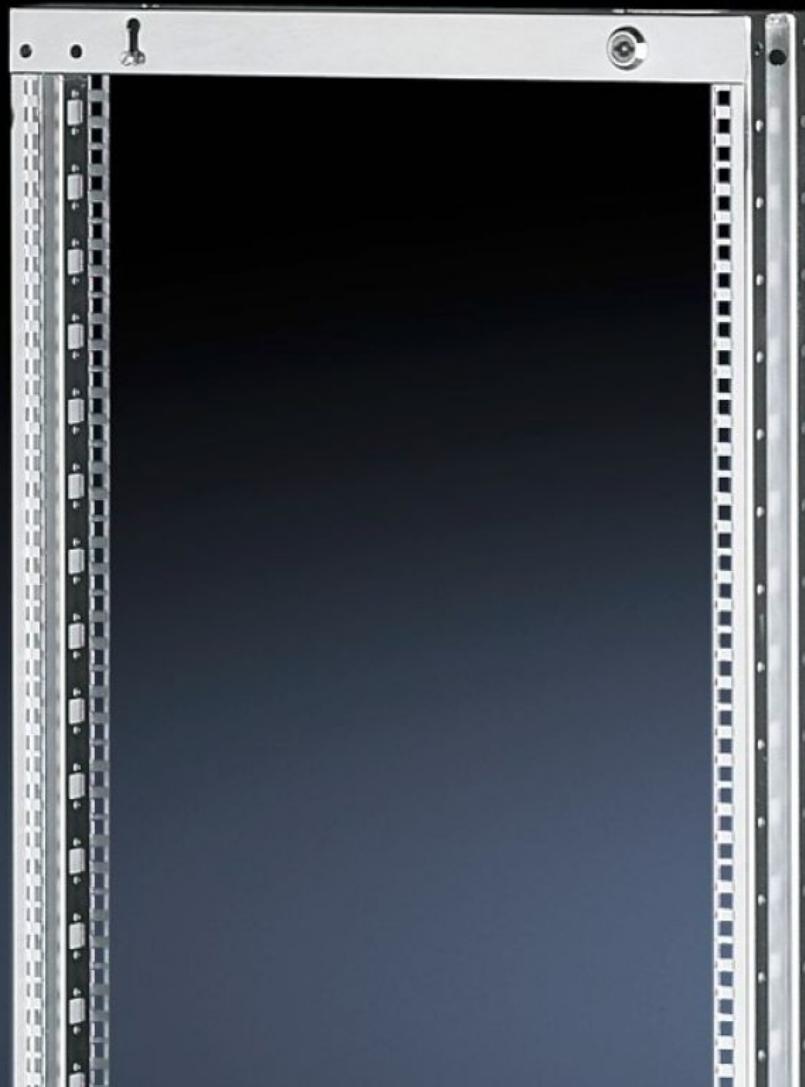


Rittal – The System.

Faster – better – everywhere.

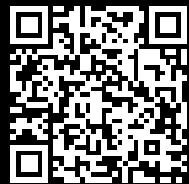

SR 2340.700

Pivoting Frame, large, without trim panel

State: 2026-02-09 (Source: rittal.com/ca-en)



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL


IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

SR 2340.700 - Pivoting Frame, large, without trim panel for TS, VX SE, 600 mm and 1200 mm wide enclosures

For 600 mm and 1200 mm wide enclosures, 22 - 45 U, without trim panel, to mount 482.6 mm (19") equipment.

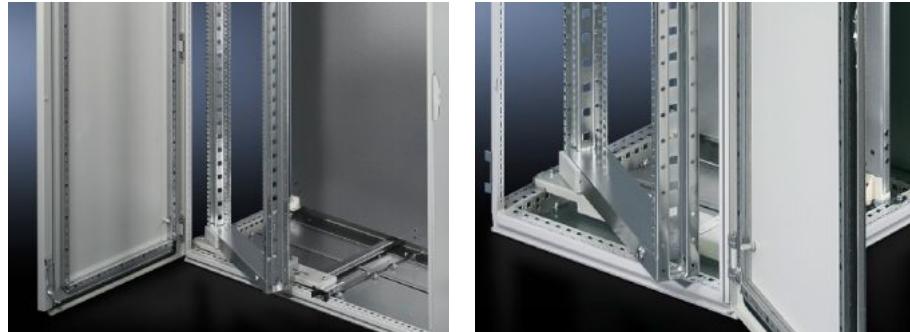

Features

Model No.	SR 2340.700
Product description	To mount 482.6 mm (19") equipment.
Material	Carbon steel
Surface finish	Zinc-plated
Supply includes	Cam with double-bit lock insert Parts for attaching to the installation kit
Mounting tip	Depending on the installation situation TS punched sections with mounting flange, 23 x 73 mm, or TS punched sections with mounting flange, 17 x 73 mm are required
Note	See "Technical Details" for other expansion options
Suitable for	Enclosure type: TS Width: = 600 mm = 1,200 mm Height: \geq 2,000 mm
Height units	40 U
Suitable for enclosure type	TS
Packaging unit	1 pc(s).
Net weight	12.271

Features

Gross weight 12.917

Customs tariff number 94039910

EAN 4028177021679

ETIM 9 EC002620

ETIM 8 EC002620

ECLASS 8.0 27189261