
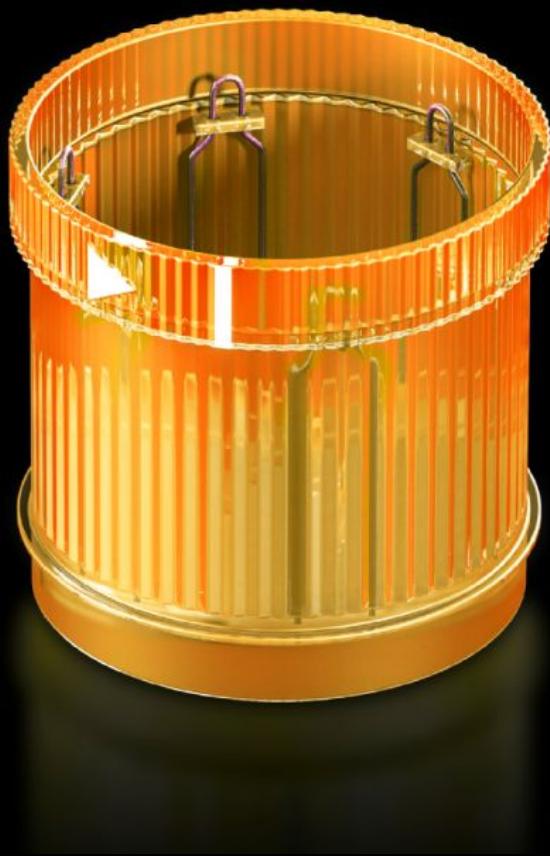


Rittal – The System.

Faster – better – everywhere.

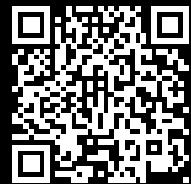

SG 2370.171

LED steady light component

State: 2026-02-11 (Source: [ittal.com/ca-en](https://www.ittal.com/ca-en))



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

SG 2370.171 - LED steady light component for signal pillar, modular

With 360° signal transmission due to optimized prism system.

Features

Model No.	SG 2370.171
Version	LED steady light component
Benefits	With 360° signal transmission thanks to optimized prism system Configuration of up to five components with the same voltage.
Function principle	A modular layout is possible with connection, optical and acoustic components and a label panel
Material	Housing of polyamide Cap: Transparent polycarbonate
Color	Yellow
Protection category IP to EN 60 529	IP 65, when cover or acoustic component is mounted on top
Rated operating voltage	230 V
Packaging unit	1 pc(s).
Net weight	0.072
Gross weight	0.073
Customs tariff number	85311095
EAN	4028177953611
ETIM 9	EC000232
ETIM 8	EC000232
ECLASS 8.0	27371220

Approvals

Approvals	UL + C-UL (listed)
Explanations	Declaration of conformity
