


# Rittal – The System.

Faster – better – everywhere.

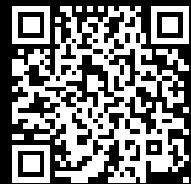

## SG 2371.001

### Flashing light component

State: 2026-02-18 (Source: [rittal.com/ca-en](https://rittal.com/ca-en))



ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP

# SG 2371.001 - Flashing light component for signal pillar, modular

With 360° signal transmission due to optimized prism system.

## Features

Model No.	SG 2371.001
Version	Flashing light component
Benefits	<p>Easy mounting and contact via bayonet fastener.</p> <p>With 360° signal transmission thanks to optimized prism system</p> <p>Configuration of up to five components with the same voltage.</p> <p>Components are available in a range of colors and voltages.</p>
Function principle	A modular layout is possible with connection, optical and acoustic components and a label panel
Material	Housing of polyamide Cap: Transparent polycarbonate
Color	Red
Protection category IP to EN 60 529	IP 65, when cover or acoustic component is mounted on top
Rated operating voltage	24 V (DC)
Packaging unit	1 pc(s).
Net weight	0.081 kg
Gross weight	0.085 kg
Customs tariff number	85311095
ETIM 9	EC000232
ETIM 8	EC000232
ECLASS 8.0	27371220
Product description	SG LED stroboscopic light component, red

# Approvals

---

Approvals	UL + C-UL (listed)
Explanations	Declaration of conformity

---