

# Rittal – The System.

Faster – better – everywhere.



## SZ 2561.200

State: 2026-05-22 (Source: [rittal.com/ca-en](https://www.rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 2561.200 - with metric knockouts, for AX

Simply break through the plastic on the knockouts for cable glands. Additional rectangular cut-outs and reinforcement frames allow the cable gland to be installed directly (modular).

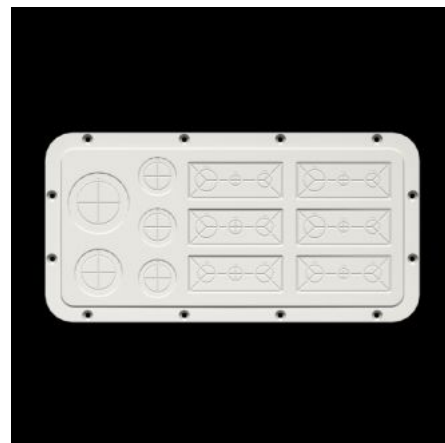

## Features

Model No.	SZ 2561.200
Product description	Simply break through the plastic on the knockouts for cable glands. Additional rectangular cut-outs and reinforcement frames allow the cable gland to be installed directly (modular).
Material	Plastic to UL 94-V0
Color	RAL 7035
Number of rectangular cutouts information	1x rectangular cutout takes 10 sealing inserts, small
Number of rectangular cutouts	2
Note	The assignment of the flange plate size can be found on the respective housings
No. of metric knockouts	2 x M12 1 x M16 2 x M20 1 x M25 2 x M32
Dimensions	Width: 256 mm Depth: 149 mm

# Features

Suitable for	Enclosure type: AX
Gland plate	Size: 1
Operating temperature range	-40 °C...80 °C
Protection category IP to EN 60529	IP 66 if correctly installed
Type rating according to UL 50E	Type 1 Type 12
Packaging unit	1 pc(s).
Net weight	0.24 kg
Gross weight	0.25 kg
Customs tariff number	39269097
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421
Product description	SZ Plastic gland plates, for AX, for cable entry, modular, pre-punched, WD: 256x149 mm, for gland plates size 1

# Approvals

Approvals	UL + C-UL - FTTA
-----------	------------------