


Rittal – The System.

Faster – better – everywhere.

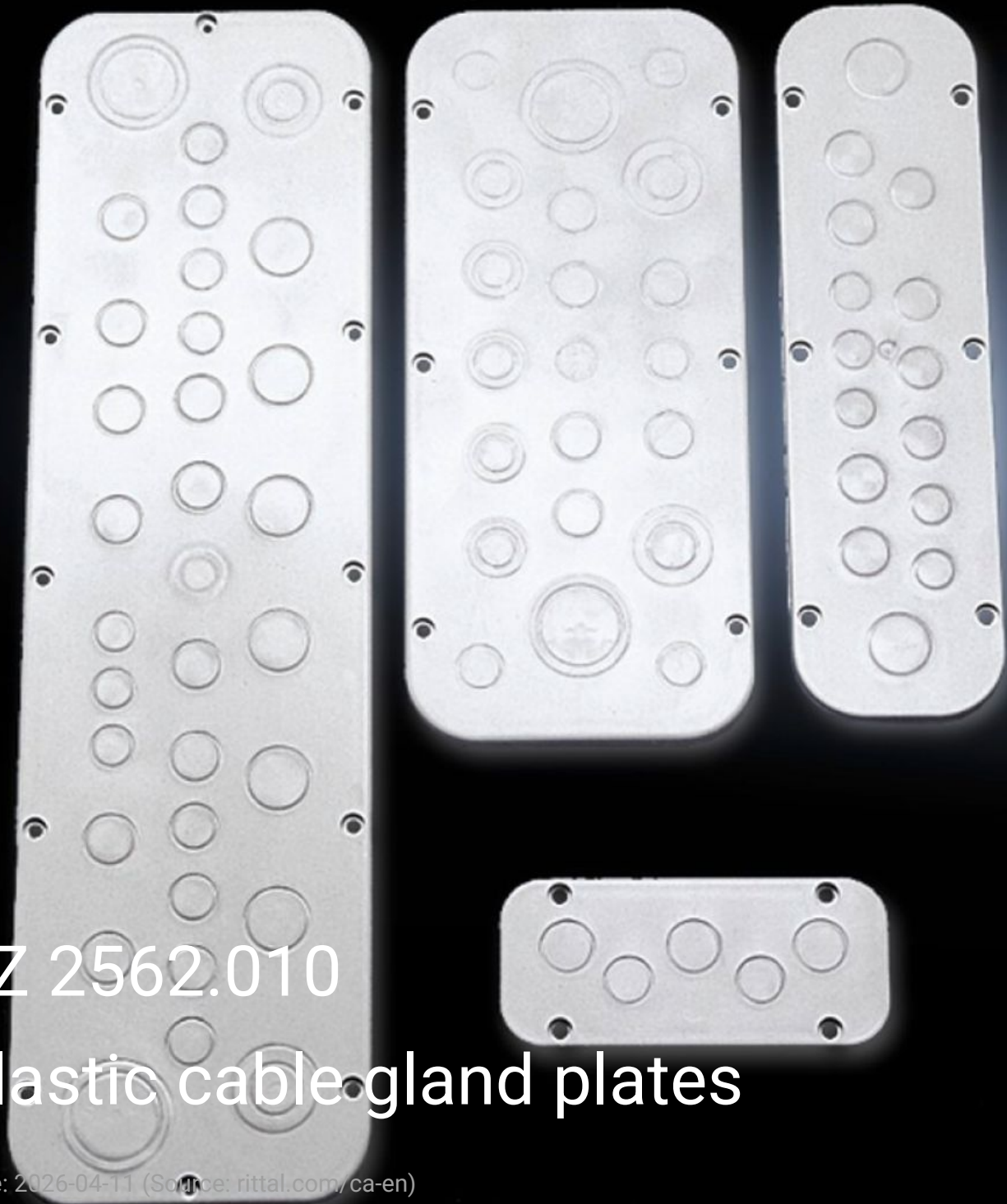

SZ 2562.010

Plastic cable gland plates

State: 2026-04-11 (Source: rittal.com/ca-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2562.010 - Plastic cable gland plates with metric knockouts

With pre-punched holes for cable glands.

Features

| | |
|------------------------------------|---------------------------------------------------------------------------------|
| Model No. | SZ 2562.010 |
| Product description | With pre-punched holes for cable glands. Used with standard flange plate seal. |
| Color | RAL 7035 |
| Note | The assignment of the flange plate size can be found on the respective housings |
| No. of metric knockouts | 2 x M12 4 x M16 4 x M20 10 x M25 4 x M32 4 x M40 2 x M50 |
| Dimensions | Width: 339 mm Depth: 149 mm |
| Suitable for | Enclosure type: AE |
| Gland plate | Size: 4 |
| Operating temperature range | -40 °C...70 °C |
| Protection category IP to EN 60529 | IP 55 if correctly installed |
| Packaging unit | 5 pc(s). |
| Net weight | 0.95 kg |
| Gross weight | 1 kg |
| Customs tariff number | 39269097 |
| ETIM 9 | EC000211 |

Features

| | |
|---------------------|-------------------------------------------------------------------------------|
| ETIM 8 | EC000211 |
| ECLASS 8.0 | 27142421 |
| Product description | SZ Plastic cable gland plate, with metric knock-outs, WD: 339x149 mm, size: 4 |
