


# Rittal – The System.

Faster – better – everywhere.

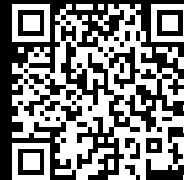

## SZ 2562.200

State: 2025-07-18 (Source: [rittal.com/ca-en](https://www.rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 2562.200 - with metric knockouts, for AX

Simply break through the plastic on the knockouts for cable glands. Additional rectangular cut-outs and reinforcement frames allow the cable gland to be installed directly (modular).



## Features

Model No.	SZ 2562.200
Product description	Simply break through the plastic on the knockouts for cable glands. Additional rectangular cut-outs and reinforcement frames allow the cable gland to be installed directly (modular).
Material	Plastic to UL 94-V0
Color	RAL 7035
Number of rectangular cutouts information	1x rectangular cutout takes 10 sealing inserts, small
Number of rectangular cutouts	3
Note	The assignment of the flange plate size can be found on the respective housings
No. of metric knockouts	3 x M12 2 x M16 3 x M20 3 x M25 2 x M32
Dimensions	Width: 339 mm Depth: 149 mm

# Features

Suitable for	Enclosure type: AX
Gland plate	Size: 2
Operating temperature range	-40 °C...80 °C
Protection category IP to EN 60 529	IP 66 if correctly installed
Type rating according to UL 50E	Type 1 Type 12
Number knockouts	3 2 3 3 2
Metric diameter	M12 M16 M20 M25 M32
Packaging unit	1 pc(s).
Net weight	0.3
Gross weight	0.332
Customs tariff number	39269097
EAN	4028177938403
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421

## Approvals

Approvals	UL + C-UL - FTTA
-----------	------------------