

# Rittal – The System.

Faster – better – everywhere.



## SZ 2563.200

State: 2026-02-10 (Source: [ittal.com/ca-en](https://www.ittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE



SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 2563.200 - with metric knockouts, for AX

Simply break through the plastic on the knockouts for cable glands. Additional rectangular cut-outs and reinforcement frames allow the cable gland to be installed directly (modular).

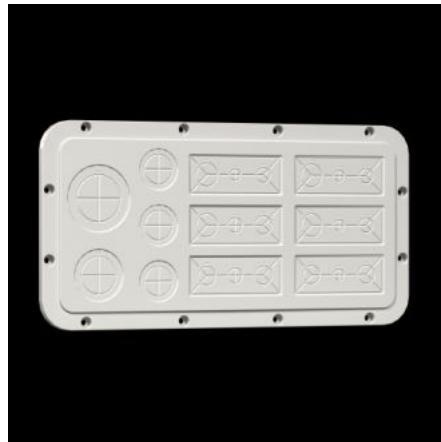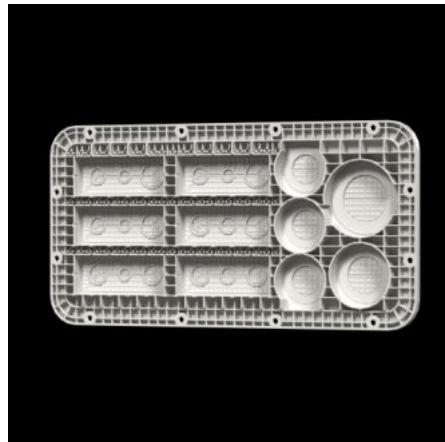

## Features

Model No.	SZ 2563.200
Product description	Simply break through the plastic on the knockouts for cable glands. Additional rectangular cut-outs and reinforcement frames allow the cable gland to be installed directly (modular).
Material	Plastic to UL 94-V0
Color	RAL 7035
Number of rectangular cutouts information	1x rectangular cutout takes 10 sealing inserts, small
Number of rectangular cutouts	4
Note	The assignment of the flange plate size can be found on the respective housings
No. of metric knockouts	4 x M12 3 x M16 5 x M20 3 x M25 1 x M32 1 x M40
Dimensions	Width: 447 mm Depth: 149 mm

# Features

Suitable for	Enclosure type: AX
Gland plate	Size: 3
Operating temperature range	-40 °C...80 °C
Protection category IP to EN 60 529	IP 66 if correctly installed
Type rating according to UL 50E	Type 1 Type 12
Number knockouts	4 3 5 3 1 1
Metric diameter	M12 M16 M20 M25 M32 M40
Packaging unit	1 pc(s).
Net weight	0.42
Gross weight	0.48
Customs tariff number	39269097
EAN	4028177938410
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421

# Approvals

Approvals	UL + C-UL - FTTA
-----------	------------------