

Rittal – The System.

Faster – better – everywhere.



SZ 2565.200

State: 2026-05-22 (Source: rittal.com/ca-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE



SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2565.200 - with metric knockouts, for AX

Simply break through the plastic on the knockouts for cable glands. Additional rectangular cut-outs and reinforcement frames allow the cable gland to be installed directly (modular).

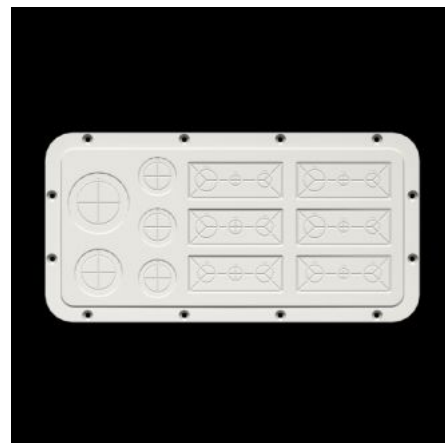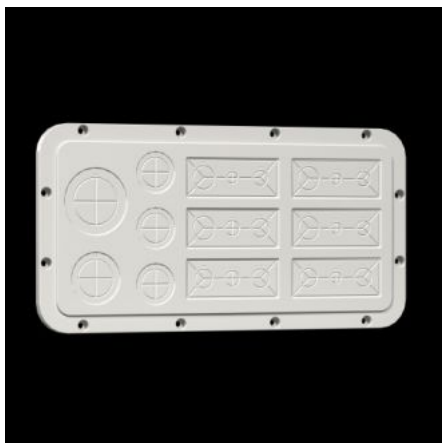

Features

| | |
|---|--|
| Model No. | SZ 2565.200 |
| Product description | Simply break through the plastic on the knockouts for cable glands. Additional rectangular cut-outs and reinforcement frames allow the cable gland to be installed directly (modular). |
| Material | Plastic to UL 94-V0 |
| Color | RAL 7035 |
| Number of rectangular cutouts information | 1x rectangular cutout takes 10 sealing inserts, small |
| Number of rectangular cutouts | 5 |
| Note | The assignment of the flange plate size can be found on the respective housings |
| No. of metric knockouts | 4 x M12 4 x M16 4 x M20 3 x M25 1 x M32 1 x M40 |
| Dimensions | Width: 301 mm Depth: 221 mm |

Features

| | |
|------------------------------------|---|
| Suitable for | Enclosure type: AX |
| Gland plate | Size: 5 |
| Operating temperature range | -40 °C...80 °C |
| Protection category IP to EN 60529 | IP 66 if correctly installed |
| Type rating according to UL 50E | Type 1 Type 12 |
| Packaging unit | 1 pc(s). |
| Net weight | 0.4 kg |
| Gross weight | 0.418 kg |
| Customs tariff number | 39269097 |
| ETIM 9 | EC000211 |
| ETIM 8 | EC000211 |
| ECLASS 8.0 | 27142421 |
| Product description | SZ Plastic gland plates, for AX, for cable entry, modular, pre-punched, WD: 301x221 mm, for gland plates size 5 |

Approvals

| | |
|-----------|------------------|
| Approvals | UL + C-UL - FTTA |
|-----------|------------------|