


Rittal – The System.

Faster – better – everywhere.

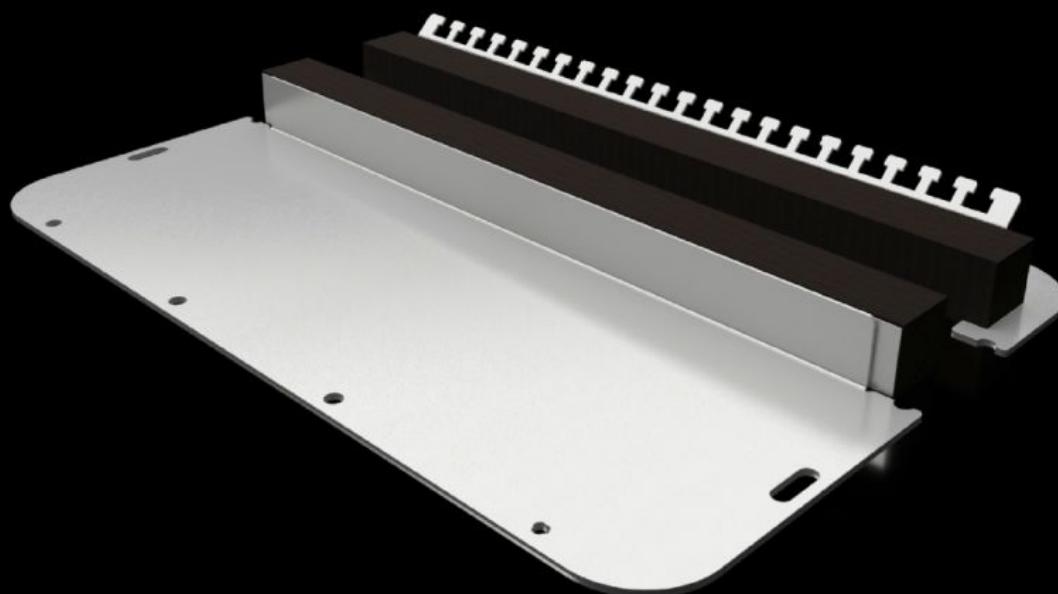

SZ 2566.450

Flange plate in two parts with elastic clamping profile

State: 2025-06-24 (Source: [rittal.com/ca-en](https://www.rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2566.450 - Flange plate in two parts with elastic clamping profile for AX

The split flange plate allows easy mounting on the housing and offers various installation options. For easy insertion of cables with or without plug connections into the housing. The special holes in the flange plate ensure automatic equipotential bonding when screwed together. Bolts, clamps or grounding cables are no longer necessary.

Features

Model No.	SZ 2566.450
Version	Two-piece
Material	Carbon steel
Color	RAL 7035
Supply includes	Assembly components
Note	The assignment of the flange plate size can be found on the respective housings When installing in enclosure width >760 mm, 2 PUs are required
Dimensions	Width: 401 mm Depth: 221 mm
Suitable for	Enclosure type: AX
Suitable for Model No.	1110.000 1114.000 1130.000 1213.000 1350.000 1115.000 1214.000
Gland plate	Size: 6
Packaging unit	1 pc(s).
Net weight	1.3
Gross weight	1.36

Features

PCF per pack (cradle-to-gate)	5.2 kg CO2 eq (Cat B)
Note on PCF category	Category B: PCF value (cradle-to-gate) based on the product weight, approximately calculated and self-declared
Customs tariff number	73269098
EAN	4028177973138
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421