


Rittal – The System.

Faster – better – everywhere.

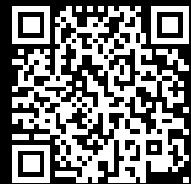

AX 2572.100

Metal gland plate

State: 2026-02-01 (Source: [ittal.com/ca-en](https://www.ittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AX 2572.100 - Metal gland plate with metric knockouts, for AX

Simply knock out the holes for the cable glands with a screwdriver.

Features

Model No.	AX 2572.100
Product description	Simply knock out the holes for the cable glands with a screwdriver.
Material	Carbon steel
Color	RAL 7035
Note	The assignment of the flange plate size can be found on the respective housings
No. of metric knockouts	6 x M16 4 x M20 10 x M25 2 x M32 2 x M40
Dimensions	Width: 339 mm Depth: 149 mm
Suitable for	Enclosure type: AX
Gland plate	Size: 2
Protection category IP to EN 60 529	IP 66 if correctly installed
Type rating according to UL 50E	Type 1 Type 12K
Number knockouts	6 4 10 2 2

Features

Metric diameter	M16 M20 M25 M32 M40
Packaging unit	1 pc(s).
Net weight	0.6
Gross weight	0.605
PCF/VE (cradle-to-gate)	3 kg CO2 eq (Cat B)
Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared
Customs tariff number	73079100
EAN	4028177925236
E-Number Sweden	E3465296
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421

Approvals

Approvals	UL + C-UL - FTTA
-----------	------------------