
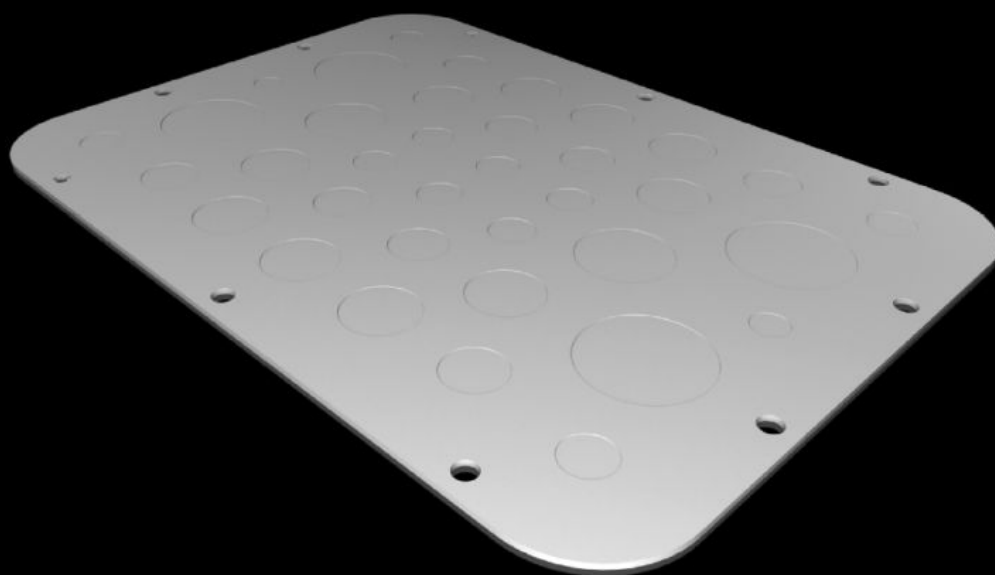


# Rittal – The System.

Faster – better – everywhere.

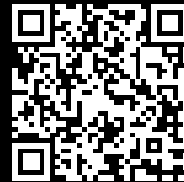

## AX 2575.100

### Metal gland plate

State: 2025-08-06 (Source: [rittal.com/ca-en](https://www.rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AX 2575.100 - Metal gland plate with metric knockouts, for AX

Simply knock out the holes for the cable glands with a screwdriver.

## Features

Model No.	AX 2575.100
Product description	Simply knock out the holes for the cable glands with a screwdriver.
Material	Carbon steel
Color	RAL 7035
Note	The assignment of the flange plate size can be found on the respective housings
No. of metric knockouts	2 x M12 10 x M16 8 x M20 10 x M25 2 x M32 4 x M40
Dimensions	Width: 301 mm Depth: 221 mm
Suitable for	Enclosure type: AX
Gland plate	Size: 5
Protection category IP to EN 60529	IP 66 if correctly installed
Type rating according to UL 50E	Type 1 Type 12K
Number knockouts	2 10 8 10 2 4

## Features

Metric diameter	M12
	M16
	M20
	M25
	M32
	M40
Packaging unit	1 pc(s).
Net weight	0.795
Gross weight	0.806
PCF/VE (cradle-to-gate)	4.1 kg CO2 eq (Cat B)
Information regarding the PCF class	Category B: PCF value (cradle-to-gate) calculated approximately on the basis of the product weight and self-declared
Customs tariff number	73079100
EAN	4028177925106
E-Number Sweden	E3465299
ETIM 9	EC000211
ETIM 8	EC000211
ECLASS 8.0	27142421

## Approvals

Approvals	UL + C-UL - FTTA
-----------	------------------