


Rittal – The System.

Faster – better – everywhere.

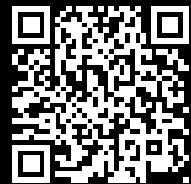

FT 2784.000

Acrylic glazed cover

State: 2026-02-08 (Source: [ittal.com/ca-en](https://www.ittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



FT 2784.000 - Acrylic glazed cover

To protect display and control components in standard 19" or metric dimensions.

Features

| | |
|-------------------------------------|--|
| Model No. | FT 2784.000 |
| Version | metric |
| Product description | With security lock, lock no. 3524 E. |
| Material | Frame: Extruded aluminum sections with die-cast corner pieces Glass panel: Smoked acrylic |
| Supply includes | Hinges and assembly components. Incl. lock insert # 3524 E |
| Protection category IP to EN 60 529 | IP 54 |
| Dimensions | Width: 400 mm Height: 200 mm Depth: 47.5 mm |
| Visible area | Viewing window width: 360 mm Viewing window height: 179.5 mm |
| Build depth for components (max.) | 43 mm |
| Packaging unit | 1 pc(s). |
| Net weight | 1.3 |
| Gross weight | 1.4 |
| Customs tariff number | 39205100 |
| EAN | 4028177032279 |
| ETIM 9 | EC002527 |
| ETIM 8 | EC002527 |
| ECLASS 8.0 | 27182301 |