


Rittal – The System.

Faster – better – everywhere.

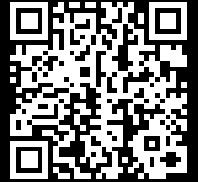

SK 3173.100 Chopped fiber filter mat

State: 2026-06-25 (Source: [rittal.com/ca-en](https://www.rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SK 3173.100 - Chopped fiber filter mat

Replacement filter mats for roof fans, filter fans or thermoelectric coolers to effectively protect control enclosure components from dirt, dust and water.

Features

Model No.	SK 3173.100
Version	for filter fans
Product description	Made of chopped-fiber mat with a progressive construction. Temperature-resistant to 100 °C, self-extinguishing category F1 to DIN 53 438. Dust-laden air side: Open structure. Clean air side: Closed structure. Reliable filtering of virtually all types of dust from a particle size of 10 µm.
Material	Chemical fibers
Note	Not suitable for use in EMC filter fans.
Suitable for Model No.	3243.... 3244.... 3245....
Dimensions	Width: 289 mm Height: 289 mm Depth: 17 mm
Filter class	to DIN EN 779: G3 to DIN EN ISO 16890: ISO coarse 50%
Packaging unit	5 pc(s).
Net weight	0.1 kg
Gross weight	0.12 kg
Customs tariff number	56039390
ETIM 9	EC002513
ETIM 8	EC002513
ECLASS 8.0	27180706

Features

Product description	SK spare filter mats, for filter fans, for SK 3243.../3244.../3245..., WHD: 289 x 289 x 17 mm
---------------------	--

Approvals

Approvals	CSA UR + C-UR (recognized)
-----------	-------------------------------