

**Rittal – The System.**

Faster – better – everywhere.



**SK 3237.067**

**Chopped fiber filter mat**

State: 2025-09-11 (Source: [rittal.com/ca-en](https://rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SK 3237.067 - Chopped fiber filter mat

Replacement filter mats for roof fans, filter fans or thermoelectric coolers to effectively protect control enclosure components from dirt, dust and water.

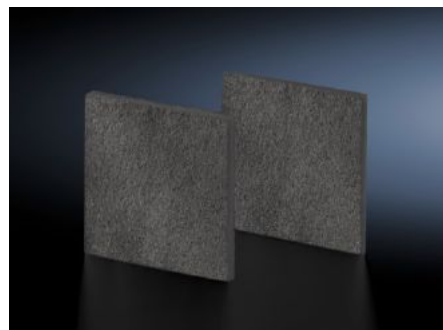

## Features

Model No.	SK 3237.067
Version	for EMC filter fans
Product description	Made of chopped-fiber mat with a progressive construction. Temperature-resistant to 100 °C, self-extinguishing category F1 to DIN 53 438. Dust-laden air side: Open structure. Clean air side: Closed structure. Reliable filtering of virtually all types of dust from a particle size of 10 µm.
Material	Copper/nickel/chrome-coated chemical fibers
Color	Anthracite
Note	Performance data, protection category, and device approvals are only guaranteed when used in conjunction with original Rittal filter mats.
Suitable for Model No.	3237.4xx/3237.8xx
Dimensions	Width: 92 mm Height: 92 mm Depth: 10 mm
Filter class	to DIN EN 779: G2 to DIN EN ISO 16890: ISO coarse 50%
Packaging unit	5 pc(s).
Net weight	0.005

# Features

Gross weight	0.01
Customs tariff number	56039390
EAN	4028177028661
ETIM 9	EC002513
ETIM 8	EC002513
ECLASS 8.0	27180706

# Approvals

Approvals	UR + C-UR (recognized)
Certificates	EAC