


Rittal – The System.

Faster – better – everywhere.

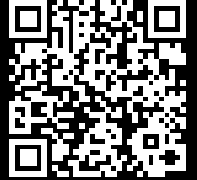

SK 3238.025 Pleated filter

State: 2026-07-10 (Source: [rittal.com/ca-en](https://www.rittal.com/ca-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SK 3238.025 - Pleated filter for filter and roof-mounted fans, cooling units and chillers

Compared to conventional chopped fiber filters, the high-quality pleated filter technology enables a significant increase in the volume flow and thus an increase in the performance of the unit as well as a reduction in energy consumption. In addition, better filtration properties ensure less dust in the enclosure or unit, and the longer service life means significantly lower service costs.

Features

Model No.	SK 3238.025
Version	for fan-and-filter units / outlet filters
Material	Pleated filter: base polyester, meltblown polycarbonate Absorber mat: 100% polyester
Color	White
Note	Not suitable for use in EMC filter fans.
Suitable for Model No.	3238.3xx 3238.7xx
Dimensions	Width: 114 mm Height: 114 mm Depth: 14 mm
Absorber mat dimensions	Width: 120 mm Height: 120 mm
Protection category IP to IEC 60529	IP 55 when mounted in filter fan/outlet filter
Packaging unit	5 pc(s).
Net weight	0.1 kg
Gross weight	0.113 kg
Customs tariff number	56039390
ETIM 9	EC002513
ETIM 8	EC002513

Features

ECLASS 8.0	27180706
------------	----------

Product description	SK folded filter IP55, for filter fan/outlet filter 3238.7xx/3238.3xx, WHD: 114x114x14 mm
---------------------	--

Approvals

Approvals	CSA UR + C-UR (recognized)
-----------	-------------------------------